

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190730174

Status:

Active

Overview:

Solderless Terminals

Description:

Avikrimp™ Ring Tongue Terminal for 10 to 12 AWG Wire, Stud Size 10 (M5), Expanded Flare, Length 27.71mm, Mylar Tape Carrier

Documents:

Drawing (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-015-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR18689

UL

E32244

General

Product Family

Ring and Spade Terminals

Series

19073

Crimp Quality Equipment

Yes

Mil-Spec

N/A

Overview

Solderless Terminals

Product Name

Avikrimp™

Type

Ring

UPC

800753077096

Physical

Barrel Type

Closed

Flammability

94V-2

Insulation

Nylon (PA)

Material - Plating Mating

Tin

Net Weight

2.191/g

Packaging Type

Adhesive Tape on Reel

Stud Size

10 (M5)

Wire Insulation Diameter

6.35mm max.

Wire Size AWG

10, 12

Wire Size mm²

4.00-6.00

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Engineering Number

C-828-10XT


Reference - Drawing Numbers

Product Specification

PS-19902-011-001, PS-19902-015-001

Sales Drawing

CCD80105

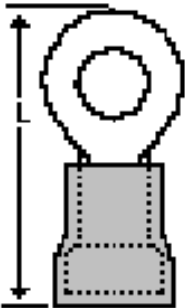

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per

-ED/01/2017 (12

January 2017)

Halogen-Free

Status

Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any

non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

19073 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION