

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191210057](#)
Status: **Active**
Overview: Solderless Terminals
Description: InsulKrimp™ Flanged Spade Tongue Terminal for 10-12 AWG Wire, Stud Size 10 (M5), Width 9.53mm, Mylar Tape Carrier

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[Product Specification PS-19902-009-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Ring and Spade Terminals
 Series [19121](#)
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview [Solderless Terminals](#)
 Product Name InsulKrimp™
 Type Spade
 UPC 800753096080

Physical

Barrel Type Closed
 Color - Resin Natural
 Flammability 94V-0
 Insulation PVC
 Material - Plating Mating Tin
 Net Weight 2.624/g
 Packaging Type Adhesive Tape on Reel
 Stud Size 10 (M5)
 Wire Insulation Diameter 6.35mm
 Wire Size AWG 10, 12
 Wire Size mm² 4.00-6.00

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number C-217-10XT

Reference - Drawing Numbers

Product Specification PS-19902-009-001, PS-19902-011-001, PS-19902-015-001
 Sales Drawing SD-19121-001

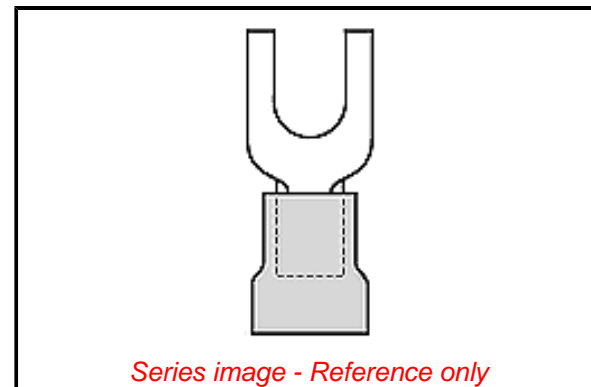

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[19121 Series](#)