

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0393900103](#)
Status: **Active**
Overview: Eurostyle™ Terminal Blocks
Description: 9.52mm Pitch Beau™ Eurostyle™ Fixed Mount PCB Terminal Block, Modular, 3 Circuits

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General

Product Family	Terminal Blocks
Series	39390
Application	N/A
Component Type	One Piece
Overview	Eurostyle™ Terminal Blocks
Product Name	Eurostyle™ Fixed Mount
Type	Euro Block
UPC	822348023004

Physical

Circuits (Loaded)	3
Entry Angle	Horizontal
Lock to Mating Part	None
Number of Rows	1
Orientation	Vertical
PC Tail Length	5.20mm
PCB Retention	None
PCB Thickness - Recommended	4.00mm
Panel Mount	No
Pitch - Mating Interface	9.53mm
Pitch - Termination Interface	9.53mm
Polarized to Mating Part	N/A
Stackable	Yes
Temperature Range - Operating	110°C
Wire Size AWG	10, 12, 14, 16, 18, 20, 22, 24, 26, 28, 30
Wire Size mm²	0.05-2.50

Electrical

Current - Maximum per Contact	30.0A
Voltage - Maximum	600V

Solder Process Data


Lead-freeProcess Capability	WAVE
Max. Cycles at Max. Process Temperature	005
Process Temperature max. C	260

Material Info

Engineering Number	MX-MSP0200N-0N
--------------------	----------------

Reference - Drawing Numbers

Sales Drawing	SD-39390-001
---------------	--------------

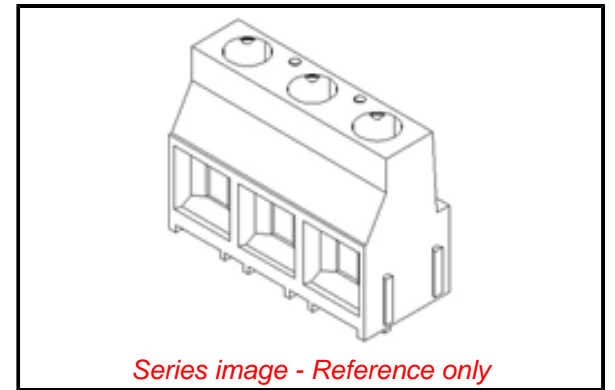

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/108/2014 (17 Dec
2014)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Reviewed

Search Parts in this Series

[39390 Series](#)