

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0191640012**
Status: **Active**
Overview: Perma-Seal™ Terminals
Description: Perma-Seal™ Female Quick Disconnect for 18-22 AWG Wire, Tab Size 6.35 x 0.81mm

Documents:

Drawing (PDF) Product Specification PS-19902-013-001 (PDF)
Product Specification PS-19902-011-001 (PDF) RoHS Certificate of Compliance (PDF)

General

Product Family Quick Disconnects
Series 19164
Crimp Quality Equipment Yes
Insulated Partial
MolexKits Yes
Overview Perma-Seal™ Terminals
Product Name Perma-Seal™
Type Quick Disconnect
UPC 800753113008

Physical

Barrel Type Closed
Color - Resin Red
Gender Female
Glow-Wire Compliant No
Insulation NiAc™
Lock to Mating Part None
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.943/g
Orientation Straight
Packaging Type Bag
Tab Thickness 0.81mm
Tab Width 6.35mm
Temperature Range - Operating -55°C to +125°C
Wire Insulation Diameter 5.97mm max.
Wire Size AWG 18, 20, 22

Electrical


Voltage - Maximum 600V

Material Info

Engineering Number SAA-2140

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing SD-19164-040

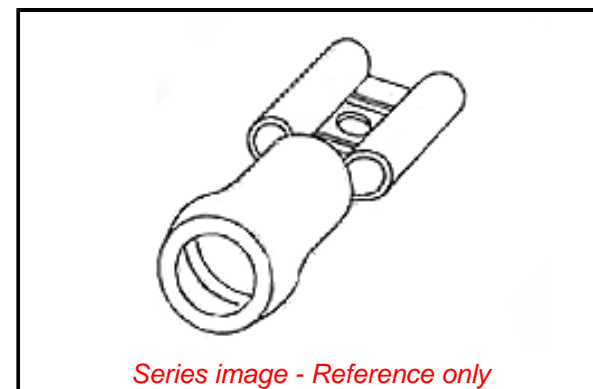

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19164 Series