

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0192000025**
Status: **Active**
Overview: Splices
Description: Avikrimp™ Seamless Butt Splice for 18-22 AWG Wire, Super Duty

Documents:

Drawing (PDF) Product Specification PS-19902-013-001 (PDF)
Product Specification PS-19902-011-001 (PDF) RoHS Certificate of Compliance (PDF)

Agency Certification

UL E32244

General

Product Family Splices
 Series 19200
 Comments Pink
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview Splices
 Product Name Avikrimp™
 UPC 800756877891

Physical

Barrel Type Closed
 Color - Resin Pink
 Flammability 94V-2
 Insulation Nylon (PA)
 Material - Metal Copper
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Net Weight 1.573/g
 Packaging Type Bag
 Temperature Range - Operating 105°C
 Wire Insulation Diameter 3.50mm
 Wire Size AWG 18, 20, 22

Electrical


Voltage - Maximum 600V

Material Info

Engineering Number AS-845 PINK

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001
 Sales Drawing SD-19200-001

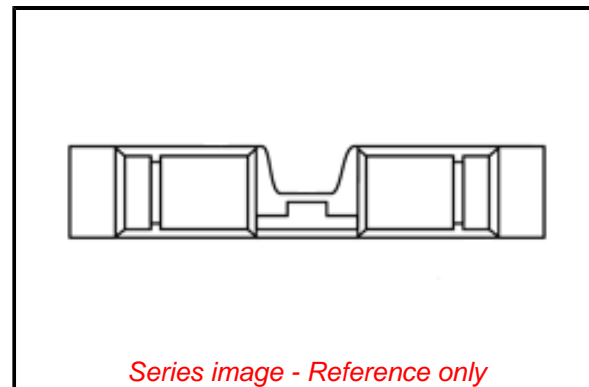

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Reviewed

Search Parts in this Series

19200 Series