

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0357180910**  
**Status:** **Active**  
**Overview:** Standard Quick-Disconnect Terminals  
**Description:** 4.75mm Tab Slip-On Terminal, Female, Wire Range 16-20 AWG (1.31-0.52mm<sup>2</sup>), 0.51mm Tab Thickness, Post-Tin Plated

**Documents:**

[Drawing \(PDF\)](#) [Packaging Specification PK-35718-001-001 \(PDF\)](#)  
[Product Specification PS-35703-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-68417-001 \(PDF\)](#)

**Agency Certification**

UL E92853

**General**

Product Family Quick Disconnects  
 Series [35718](#)  
 Crimp Quality Equipment Yes  
 Insulated No  
 Overview [Standard Quick-Disconnect Terminals](#)  
 Product Name Slip-On  
 Type Quick Disconnect  
 UPC 800753199538

**Physical**

Barrel Type Open  
 Gender Female  
 Glow-Wire Compliant No  
 Insulation None  
 Lock to Mating Part Yes  
 Material - Metal Brass  
 Material - Plating Mating Tin  
 Material - Plating Termination Tin  
 Net Weight 0.440/g  
 Orientation Straight  
 Packaging Type Reel  
 Plating min - Mating 1.016µm  
 Plating min - Termination 1.016µm  
 Polarized to Mating Part No  
 Tab Thickness 0.51mm  
 Tab Width 4.75mm  
 Temperature Range - Operating -40°C to +105°C  
 Termination Interface: Style Crimp or Compression  
 Wire Insulation Diameter 3.50mm max.  
 Wire Size AWG 16, 18, 20  
 Wire Size mm<sup>2</sup> 0.50-1.30


**Electrical**

Voltage - Maximum 250V

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification PK-35718-001-001  
 Product Specification PS-35703-001-001, PS-68417-001  
 Sales Drawing SD-35718-09\*0

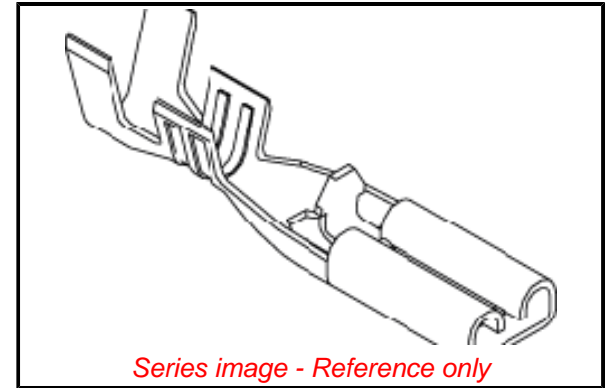

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 ED/30/2017 (7 July  
 2017)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

**China RoHS**

**Green Image**

**Not Relevant**

**Not Contained**

**Search Parts in this Series**

[35718 Series](#)

**Use With**

4.75mm Tab

This document was generated on 07/28/2017

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**