

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0190990028**
Status: **Active**
Overview: Solderless Terminals
Description: InsulKrimp™ Snap Spade for 16-14 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier, Blue

Documents:

Drawing (PDF) Product Specification PS-19902-015-001 (PDF)
Product Specification PS-19902-009-001 (PDF) RoHS Certificate of Compliance (PDF)
Product Specification PS-19902-011-001 (PDF)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Ring and Spade Terminals
 Series 19099
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview Solderless Terminals
 Product Name InsulKrimp™
 Type Spade Snap
 UPC 800753089105

Physical

Barrel Type Closed
 Color - Resin Blue
 Flammability 94V-0
 Insulation PVC
 Material - Plating Mating Tin
 Net Weight 0.718/g
 Packaging Type Adhesive Tape on Reel
 Stud Size 5-6 (M3-3.5)
 Wire Insulation Diameter 4.40mm max.
 Wire Size AWG 14, 16

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number BB-2707-06XT

Reference - Drawing Numbers

Product Specification PS-19902-009-001, PS-19902-011-001,
 PS-19902-015-001
 Sales Drawing BBCD20502

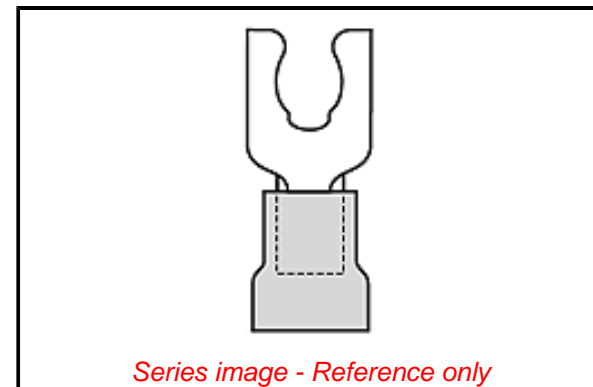

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

19099 Series