

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0194030011**  
**Status:** **Active**  
**Overview:** Self-Contained Power Connector (SCPC)  
**Description:** Self-Contained Power Connector for 2 Circuit Round Cable with Ground, 14 AWG, Insulation Diameter 15.24mm

**Documents:**

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)

**General**

Product Family	I/O Connectors
Series	<u>19403</u>
Application	Wire-to-Wire
Comments	2 Circuit SEOW/SJEW versions specifically engineered-accommodate round jacketed, stranded conductor power cords typically found in RV slide-out manufacturing applications
Component Type	Plug, Receptacle
Overview	<u>Self-Contained Power Connector (SCPC)</u>
Product Literature Order No	987650-0531
Product Name	SCPC
Type	N/A
UPC	756054403297


**Physical**

Circuits (Loaded)	2
Circuits (maximum)	2
Circuits Detail	2 Circuits with Ground
Color - Resin	Clear, Natural
Durability (mating cycles max)	250
Lock to Mating Part	Yes
Material - Metal	High Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polycarbonate, Polyester
Net Weight	28.983/g
Number of Rows	1
Orientation	Vertical
PCB Retention	N/A
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	10.10mm
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Polarized to Mating Part	Yes
Surface Mount Compatible (SMC)	N/A
Temperature Range - Operating	-35°C to +85°C
Termination Interface: Style	IDT or Pierce
Wire Insulation Diameter	15.24mm
Wire Size AWG	14

**Electrical**

Current - Maximum per Contact	15.0A
Voltage - Maximum	600V

**Material Info**

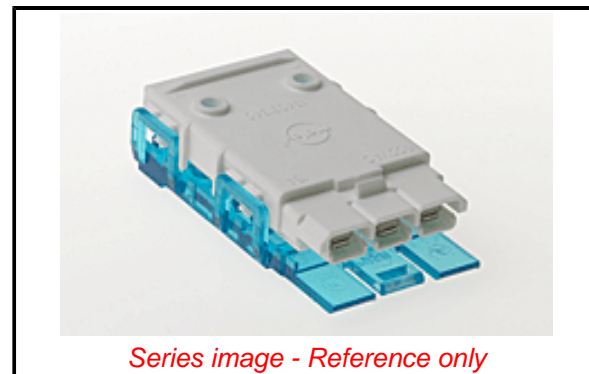

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/108/2014 (17 Dec 2014)

**Halogen-Free**

**Status**

**Not Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

19403 Series

**Mates With**

19403-0011 Self-Contained Power Connector for 2 Circuit Round Cable with Ground, 14 AWG, Insulation Diameter 15.24mm

**Use With**

19045-3180 Safety Cap, 19426-0001 Weather Tight Male Boot for 12-14 AWG Round Stranded Cable, 19426-0002 Weather Tight Female Boot for 12-14 AWG Round Stranded Cable

Reference - Drawing Numbers  
Sales Drawing

SD-19045-001-001, SD-19403-147

This document was generated on 06/09/2017

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**