

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0191180090**
Status: **Active**
Overview: Solderless Terminals
Description: Krimptite™ Flanged Spade Tongue Terminal for 10-12 AWG Wire, Stud Size 10 (M5), Length 19.56mm, Mylar Tape Carrier

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Ring and Spade Terminals
 Series 19118
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview Solderless Terminals
 Product Name Krimptite™
 Type Spade
 UPC 800753093881

Physical

Barrel Type Closed
 Insulation None
 Material - Plating Mating Tin
 Net Weight 2.232/g
 Packaging Type Adhesive Tape on Reel
 Stud Size 10 (M5)
 Wire Size AWG 10, 12
 Wire Size mm² 4.00-6.00

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number C-117-10T

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-015-001
 Sales Drawing SD-19118-002

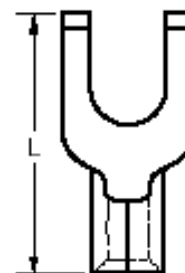

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS Green Image
 ELV Not Relevant
 RoHS Phthalates Not Contained

Search Parts in this Series

19118 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION