

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0190670369**  
**Status:** **Active**  
**Overview:** Solderless Terminals  
**Description:** NylaKrimp™ Funnel Entry Ring Tongue Terminal for 4/0 AWG Wire, Stud Size 5/16" (M8)

**Documents:**

[Drawing \(PDF\)](#) [Product Specification PS-19902-016-001 \(PDF\)](#)  
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-19902-013-001 \(PDF\)](#)

**General**

Product Family	Ring and Spade Terminals
Series	<u>19067</u>
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	<u>Solderless Terminals</u>
Product Name	NylaKrimp™
Type	Ring
UPC	822350727082

**Physical**


Barrel Type	Closed - Brazed
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	51.570/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	5/16" (M8)
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	23.98mm max.
Wire Size AWG	4/0

**Material Info**

Engineering Number L-995-56

**Reference - Drawing Numbers**

Product Specification	PS-19902-011-001, PS-19902-013-001, PS-19902-016-001
Sales Drawing	SD-19067-009

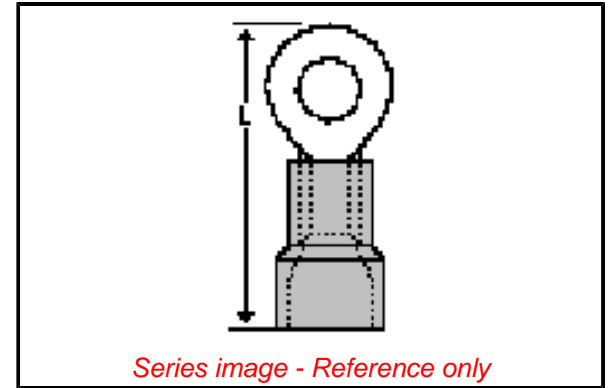

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/30/2017 (7 July 2017)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

**Search Parts in this Series**

19067 Series

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

Description	Product #
Die Set (large) for the HHLS Hydraulic Crimper	<u>0192890031</u>