

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

**Part Number:** [19006-0024](#)  
**Status:** **Active**  
**Description:** Flag Avikrimp™ Quick Disconnect, Female, for 14-16 (2.00-1.30mm²) Wire, Metal Strip, Tab 4.75 x 0.81mm

**Documents:**  
[Product Specification PS-19902-011 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-19902-014 \(PDF\)](#)

**Agency Certification**

CSA LR18689  
UL E79133

**General**

Product Family Quick Disconnects  
Series [19006](#)  
Crimp Quality Equipment Yes  
Insulated Fully  
Product Name Avikrimp™  
Type Quick Disconnect  
UPC 800753031272

**Physical**

Barrel Type Closed  
Flammability 94V-2  
Gender Female  
Glow-Wire Compliant No  
Insulation Nylon (PA)  
Lock to Mating Part None  
Net Weight 1.352/g  
Orientation Flag  
Packaging Type Reel  
Polarized to Mating Part No  
Tab Thickness 0.81mm  
Tab Width 4.75mm  
Temperature Range - Operating -65°C to +105°C  
Wire Insulation Diameter 4.32mm max.  
Wire Size AWG 14, 16  
Wire Size mm² 1.30 - 2.00

**Electrical**


Voltage - Maximum 600V

**Material Info**

Old Part Number BB-5225Z

**Reference - Drawing Numbers**

Product Specification PS-19902-011, PS-19902-014

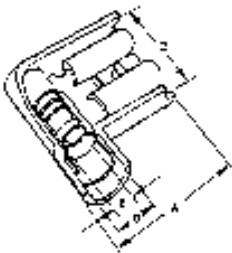

Series

image - Reference only

**EU RoHS**  
**ELV and RoHS**  
**Compliant**  
**REACH SVHC**  
Not Reviewed  
**Low-Halogen Status**  
**Not Reviewed**

**China RoHS**



**Need more information on product environmental compliance?**  
  
Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
For a multiple part number RoHS Certificate of Compliance, [click here](#)  
  
Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**  
[19006Series](#)

**Application Tooling | FAQ**  
*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*  
**Global**

| Description                                                                                                            | Product #                  |
|------------------------------------------------------------------------------------------------------------------------|----------------------------|
| ASP Tool Kit, Perishable, Used in an ASP-101RF Press that Processes Metal Strip Product Applicator Perishable Tool Kit | <a href="#">0198032080</a> |
| Rear Feed Mini-Mac™ Applicator for Flag Quick Disconnect Female Terminals, 14-16 AWG Wire                              | <a href="#">0638026300</a> |

This document was generated on 08/30/2013

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**