

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0191640070**  
**Status:** **Active**  
**Overview:** Perma-Seal™ Terminals  
**Description:** Perma-Seal™ Spade Tongue Terminal for 10-12 AWG Wire, Stud Size 8 (M4)

**Documents:**

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)  
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR18689  
 UL E32244

**General**

Product Family Ring and Spade Terminals  
 Series 19164  
 Crimp Quality Equipment Yes  
 Mil-Spec N/A  
 MolexKits Yes  
 Overview Perma-Seal™ Terminals  
 Product Name Perma-Seal™  
 Type Spade  
 UPC 800753113541

**Physical**


Barrel Type Closed  
 Insulation NiAc™  
 Material - Plating Mating Tin  
 Net Weight 1.960/g  
 Packaging Type Bag  
 Plating min - Mating 2.540µm  
 Plating min - Termination 2.540µm  
 Stud Size 8 (M4)  
 Wire Insulation Diameter 7.87mm  
 Wire Size AWG 10, 12  
 Wire Size mm² 3.09-5.01

**Material Info**

Engineering Number SC-241-08

**Reference - Drawing Numbers**

Product Specification PS-19902-011-001, PS-19902-013-001  
 Sales Drawing SD-19164-048

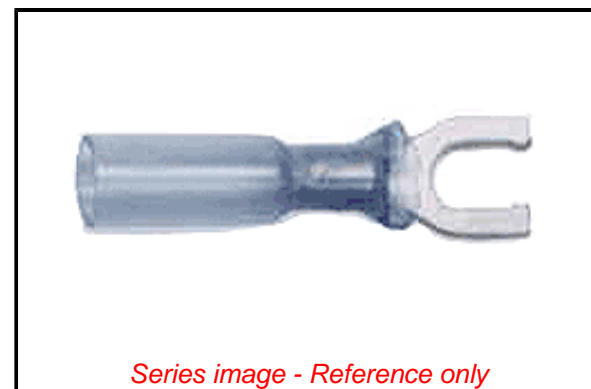

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 ED/30/2017 (7 July  
 2017)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product  
 environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any  
 non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

19164 Series