

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0190840009**  
**Status:** **Active**  
**Overview:** Solderless Terminals  
**Description:** Open Barrel Star Ring , Tin-Plated Steel, for 14-18 AWG Wire Range, Stud Size 10 (M5)

**Documents:**

[Drawing \(PDF\)](#) [Product Specification PS-19902-011-001 \(PDF\)](#)  
[Product Specification PS-19902-006-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR18689  
 UL E32244

**General**

Product Family Ring and Spade Terminals  
 Series 19084  
 Crimp Quality Equipment Yes  
 Mil-Spec N/A  
 Overview Solderless Terminals  
 Product Name N/A  
 Type Ring  
 UPC 800755080230

**Physical**

Barrel Type Open  
 Insulation None  
 Material - Plating Mating Tin  
 Net Weight 0.735/g  
 Packaging Type Reel  
 Plating min - Mating 2.540µm  
 Plating min - Termination 2.540µm  
 Stud Size 10 (M5)  
 Termination Interface: Style Crimp or Compression  
 Wire Insulation Diameter N/A  
 Wire Size AWG 14, 16, 18  
 Wire Size mm<sup>2</sup> 0.80-2.00

**Solder Process Data**


Lead-freeProcess Capability N/A

**Material Info**

Engineering Number SRZ-S-4129-10

**Reference - Drawing Numbers**

Product Specification PS-19902-006-001, PS-19902-011-001  
 Sales Drawing SD-19084-001

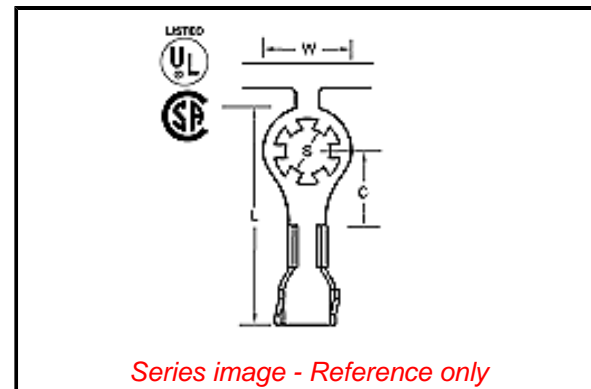

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 ED/30/2017 (7 July  
 2017)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product  
 environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any  
 non-product compliance questions.

China ROHS Green Image  
 ELV Not Relevant  
 RoHS Phthalates Not Contained

**Search Parts in this Series**

19084 Series

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**