

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0190670105**  
**Status:** **Active**  
**Overview:** Solderless Terminals  
**Description:** NylaKrimp™ Funnel Entry Ring Tongue Terminal for 1/0 AWG Wire, Stud Size 1/2" (M12)

**Documents:**

Drawing (PDF) Product Specification PS-19902-016-001 (PDF)  
Product Specification PS-19902-011-001 (PDF) RoHS Certificate of Compliance (PDF)  
Product Specification PS-19902-013-001 (PDF)

**Agency Certification**

UL E32244

**General**

Product Family Ring and Spade Terminals  
 Series 19067  
 Crimp Quality Equipment Yes  
 Mil-Spec N/A  
 Overview Solderless Terminals  
 Product Name NylaKrimp™  
 Type Ring  
 UPC 800753066915

**Physical**


Barrel Type Closed - Brazed  
 Flammability 94V-2  
 Insulation Nylon (PA)  
 Material - Plating Mating Tin  
 Net Weight 33.672/g  
 Packaging Type Bag  
 Plating min - Mating 2.540µm  
 Plating min - Termination 2.540µm  
 Stud Size 1/2" (M12)  
 Termination Interface: Style Crimp or Compression  
 Wire Insulation Diameter 17.27mm max.  
 Wire Size AWG 1

**Material Info**

Engineering Number H-982-12

**Reference - Drawing Numbers**

Product Specification PS-19902-011-001, PS-19902-013-001, PS-19902-016-001

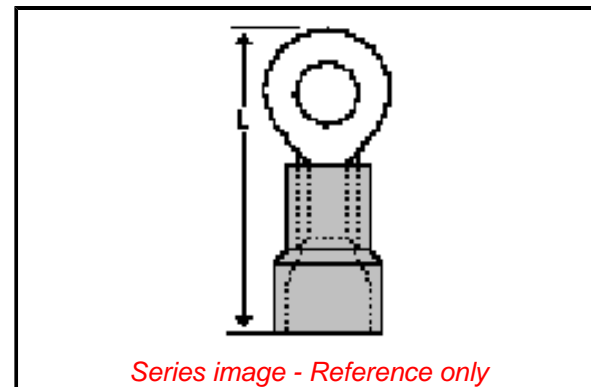

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
 -ED/01/2017 (12  
 January 2017)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

**Search Parts in this Series**

19067 Series