

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0009481094](#)
Status: **Active**
Overview: [KK® Interconnect System - Molex](#)
Description: [KK® 396 PC Board Connector, Right Angle, Polyester Connector, 5.00µm Tin \(Sn\), 9 Circuits](#)

Documents:

| | |
|-------------------------------|--|
| Drawing (PDF) | Product Specification PS-08-50-001 (PDF) |
| 3D Model | Packaging Specification PK-41815-001-000 (PDF) |
| Drawing (PDF) | RoHS Certificate of Compliance (PDF) |

Agency Certification

| | |
|-----|---------|
| CSA | LR19980 |
| UL | E29179 |

General

| | |
|----------------|---|
| Product Family | PCB Receptacles |
| Series | 41815 |
| Application | Board-to-Board, Power |
| Overview | KK® Interconnect System - Molex |
| Product Name | KK® 396 |
| UPC | 800754902113 |

Physical


| | |
|--------------------------------|---------------------------|
| Circuits (Loaded) | 9 |
| Circuits (maximum) | 9 |
| Color - Resin | Natural |
| Flammability | 94V-0 |
| Glow-Wire Compliant | No |
| Lock to Mating Part | Yes |
| Material - Metal | Phosphor Bronze |
| Material - Plating Mating | Tin |
| Material - Plating Termination | Tin |
| Material - Resin | Polyester |
| Net Weight | 3.012/g |
| Number of Rows | 1 |
| Orientation | Right Angle |
| PC Tail Length | 3.68mm |
| PCB Locator | No |
| PCB Retention | Yes |
| Packaging Type | Tray |
| Pitch - Mating Interface | 3.96mm |
| Plating min - Mating | 5.080µm |
| Plating min - Termination | 5.080µm |
| Polarized to PCB | Yes |
| Temperature Range - Operating | See Product Specification |
| Termination Interface: Style | Through Hole |

Electrical

| | |
|-------------------------------|------|
| Current - Maximum per Contact | 5.0A |
| Voltage - Maximum | 250V |

Solder Process Data

| | |
|--|------|
| Duration at Max. Process Temperature (seconds) | 005 |
| Lead-free Process Capability | WAVE |
| Max. Cycles at Max. Process Temperature | 001 |
| Process Temperature max. C | 235 |

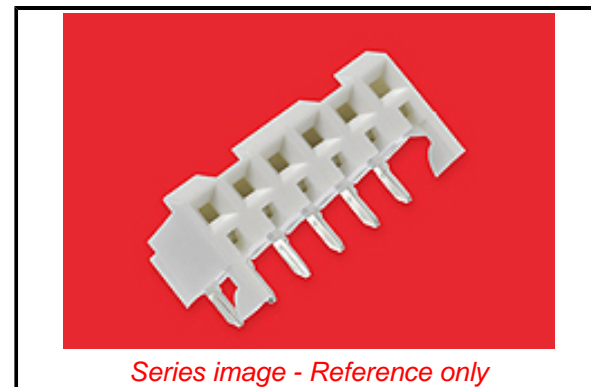

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

| | |
|-----------------|---------------|
| China ROHS | Green Image |
| ELV | Not Relevant |
| RoHS Phthalates | Not Contained |

Search Parts in this Series

[41815 Series](#)

Mates With

[KK® 396 Header 41771](#) , [41772](#) , [41791](#) , [41792](#) , [42491](#) , [42492](#) , [42891](#) , [41661](#) , [41662](#) , [41671](#) , [41672](#) , [41681](#)

Material Info

Engineering Number

A-41815-0009

Reference - Drawing Numbers

Packaging Specification

PK-41815-001-000

Product Specification

PS-08-50-001

Sales Drawing

SDA-41815-000, SDA-41815-002

This document was generated on 09/08/2017

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION