

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0393570003
Status: Active
Description: PCB TERM BLK 3.5MM 3 POLE STRAGT

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family Terminal Blocks
Series 39357
Application N/A
Component Type One Piece
Product Name Eurostyle™ Fixed Mount
Type Euro Block
UPC 756054634134

Physical

Circuits (Loaded) 3
Circuits (maximum) 3
Entry Angle Horizontal
Flammability 94V-0
Lock to Mating Part None
Number of Rows 1
Orientation Vertical
PC Tail Length 3.50mm
PCB Retention None
PCB Thickness - Recommended 1.60mm
Panel Mount No
Pitch - Mating Interface 3.50mm
Pitch - Termination Interface 3.50mm
Polarized to Mating Part No
Shrouded Fully
Stackable Yes
Surface Mount Compatible (SMC) No
Temperature Range - Operating -30°C to +85°C
Wire Size AWG 16, 18, 20, 22, 24, 26, 28
Wire Size mm² 0.20-1.00

Electrical


Current - Maximum per Contact 17.5A
Voltage - Maximum 300V

Material Info

Engineering Number MX-MTB03008-0N

Reference - Drawing Numbers

Sales Drawing SD-39357-001

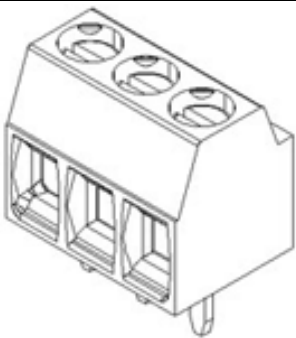

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with
Exemption 6(c)

REACH SVHC

Not Contained Per -
ED/108/2014 (17 Dec
2014)

Halogen-Free

Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

39357 Series