

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190160069

Status:


Active

Overview:

Standard Quick-Disconnect Terminals

Description:

Krimptite™ Quick Disconnect, Female, for 10-12 (5.00-3.30mm²) Wire, Box, Tab 6.35 x 0.81mm

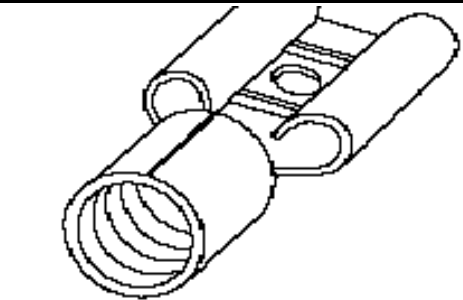

Series image - Reference only

Documents:

[Drawing \(PDF\)](#)

[Product Specification PS-19902-005-001 \(PDF\)](#)

[Product Specification PS-19902-011-001 \(PDF\)](#)

[Product Specification PS-19902-013-001 \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR18689
UL	E79133
General	
Product Family	Quick Disconnects
Series	19016
Comments	Butted Seam
Crimp Quality Equipment	Yes
Insulated	No
MolexKits	Yes
Overview	Standard Quick-Disconnect Terminals
Product Name	Krimptite™
Type	Quick Disconnect
UPC	800753034822
Physical	
Barrel Type	Closed
Gender	Female
Glow-Wire Compliant	No
Insulation	None
Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.897/g
Orientation	Straight
Packaging Type	Bag
Polarized to Mating Part	No
Tab Thickness	0.81mm
Tab Width	6.35mm
Temperature Range - Operating	Per Wire Specification
Wire Size AWG	10, 12
Electrical	
Voltage - Maximum	Per Wire Specification
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	C-1143
Reference - Drawing Numbers	
Product Specification	PS-19902-005-001, PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19016-002

EU ELV
Not Relevant

EU RoHS
Compliant
REACH SVHC
Not Contained Per -
ED/30/2017 (7 July
2017)
Halogen-Free
Status
Low-Halogen
**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS
ELV
RoHS Phthalates

Green Image
Not Relevant
Not Contained

Search Parts in this Series

19016 Series

This document was generated on 07/27/2017

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION