

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0350230006](#)
Status: **Active**
Description: 2.00mm Pitch Board-in Crimp Housing, 6 Circuits

Documents:

[3D Model](#) [Packaging Specification PK-35023-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-35023-001-001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [35023](#)
 Application Signal
 Product Name Board-In
 UPC 800754255271

Physical

Circuits (maximum) 6
 Color - Resin Natural
 Flammability 94V-0
 Gender Receptacle
 Glow-Wire Compliant No
 Material - Resin Nylon
 Net Weight 0.102/g
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 2.00mm
 Stackable No
 Temperature Range - Operating -40°C to +105°C


Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers

Packaging Specification PK-35023-001-001
 Product Specification PS-35023-001-001
 Sales Drawing SD-35023-001

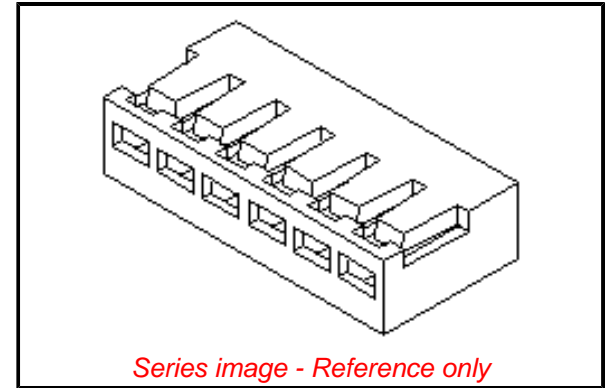

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS Green Image
 ELV Not Relevant
 RoHS Phthalates Not Contained

Search Parts in this Series

[35023 Series](#)

Use With

Straight Terminal [35044-9102](#) , [35044-9260](#)

Right Angle Terminal [35021-1201](#) ,
[35021-1301](#) , [35021-1360](#)