

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0561348100**
Status: **Active**
Overview: MicroClasp™ Wire-to-Board System
Description: 2.00mm Pitch Crimp Terminal, Female, 22-26 AWG, Phosphor Bronze, Bag

Documents:

3D Model	Application Specification 5055960001-000 (PDF)
Drawing (PDF)	Application Specification 5055960001-001 (PDF)
Application Specification 5055960000-AS-000 (PDF)	Packaging Specification SPK-56134-001-001 (PDF)
Application Specification 5055960000-AS-001 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Crimp Terminals
Series	56134
Application	Signal
Crimp Quality Equipment	Yes
Overview	MicroClasp™ Wire-to-Board System
Packaging Alternative	56134-8000 (Reel)
Product Name	MicroClasp™
UPC	800756190549


Physical

Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	36.000/mg
Packaging Type	Bag
Plating min - Mating	0.889µm
Plating min - Termination	0.914µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.25-1.70mm
Wire Size AWG	22, 24, 26
Wire Size mm²	N/A

Material Info

Reference - Drawing Numbers

Application Specification	5055960000-AS-000, 5055960000-AS-001, 5055960001-000, 5055960001-001
Packaging Specification	SPK-56134-001-001
Sales Drawing	SD-56134-002

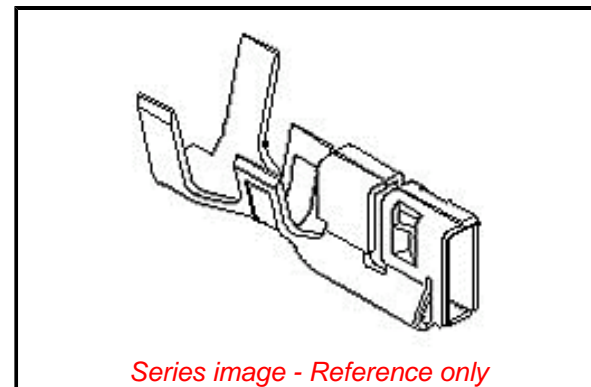

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

56134 Series

Use With

Housings 51242 , 51353 , 51382 , 505596