

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0190350002**
Status: **Active**
Overview: Snap Plugs and Receptacles
Description: Avikrimp™ Snap Plug, for 18-22 AWG Wire, Mylar Tape, 24.08mm Length

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E152602

General

Product Family Quick Disconnects
 Series 19035
 Comments Molded Nylon Insulation
 Crimp Quality Equipment Yes
 Insulated Partial
 Overview Snap Plugs and Receptacles
 Product Name Avikrimp™
 Type Snap Plug
 UPC 800756403670

Physical

Barrel Type Closed
 Color - Resin Red
 Flammability 94V-2
 Gender Male
 Glow-Wire Compliant No
 Insulation Nylon (PA)
 Lock to Mating Part None
 Material - Metal Copper
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Material - Resin Nylon
 Net Weight 1.624/g
 Orientation Straight
 Packaging Type Adhesive Tape on Reel
 Tab Thickness N/A
 Tab Width N/A
 Termination Interface: Style Crimp or Compression
 Wire Insulation Diameter 3.60mm max.
 Wire Size AWG 18, 20, 22

Electrical


Voltage - Maximum N/A

Material Info

Engineering Number A-559T

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-015-001
 Sales Drawing SD-19035-001

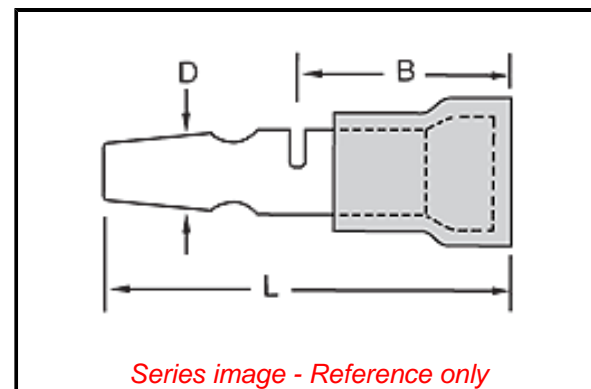

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS Not Relevant
 ELV Not Relevant
 RoHS Phthalates Not Contained

Search Parts in this Series

19035 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION