

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0395033012](#)
Status: **Active**
Overview: Eurostyle™ Terminal Blocks
Description: 3.50mm Pitch Eurostyle™ Vertical Plug, Front Wire Entry, 12 Circuits

Documents:

[3D Model](#) [Product Specification PS-39500-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family Terminal Blocks
 Series [39503](#)
 Application N/A
 Comments Front Wire Entry
 Component Type Plug
 Overview [Eurostyle™ Terminal Blocks](#)
 Product Name ESE, Eurostyle™ Pluggable
 Type Euro Block
 UPC 822350678735

Physical

Circuits (Loaded) 12
 Entry Angle Horizontal
 Lock to Mating Part None
 Number of Rows 1
 Orientation Vertical
 Panel Mount No
 Pitch - Mating Interface 3.50mm
 Pitch - Termination Interface 3.50mm
 Polarized to Mating Part Yes
 Stackable No
 Temperature Range - Operating -40°C to +105°C
 Wire Size AWG 16, 18, 20, 22, 24
 Wire Size mm² 0.20-1.31


Electrical

Current - Maximum per Contact 8.0A
 Voltage - Maximum 300V

Material Info

Reference - Drawing Numbers

Product Specification PS-39500-001-001
 Sales Drawing SD-39503-001

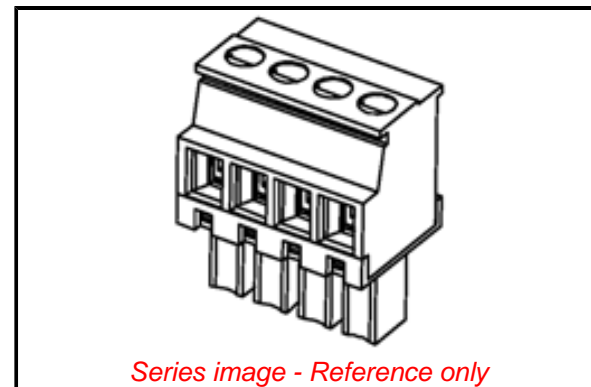

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[39503](#) Series

Mates With

[39501](#) Vertical PCB Header, [39502](#)
 Horizontal PCB Header, Most 3.50mm Pitch
 Industry Standard PCB Headers

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION