

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0191210009**
Status: **Active**
Overview: Solderless Terminals
Description: InsulKrimp™ Flanged Spade Tongue Terminal for 18-22 AWG Wire, Stud Size 10 (M5)

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-009-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Ring and Spade Terminals
 Series 19121
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview Solderless Terminals
 Product Name InsulKrimp™
 Type Spade
 UPC 800753095298

Physical


Barrel Type Closed
 Flammability 94V-0
 Insulation PVC
 Material - Plating Mating Tin
 Net Weight 0.608/g
 Packaging Type Bag
 Stud Size 10 (M5)
 Wire Insulation Diameter 3.68mm
 Wire Size AWG 18, 20, 22
 Wire Size mm² 0.25-1.50

Material Info

Engineering Number AA-215-10X

Reference - Drawing Numbers

Product Specification PS-19902-009-001, PS-19902-011-001,
 PS-19902-013-001
 Sales Drawing SD-19121-001

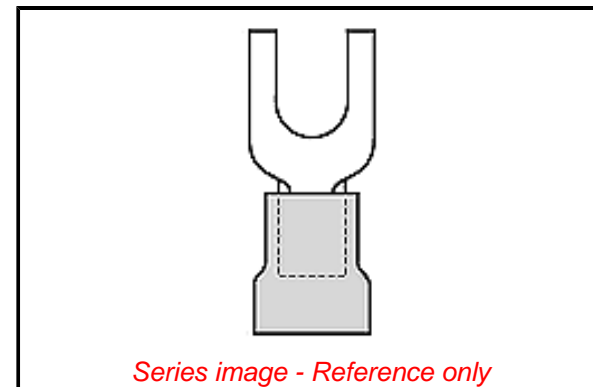

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19121 Series