

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **5025780204**  
**Status:** **Active**  
**Overview:** CLIK-Mate Wire-to-Board Connectors  
**Description:** 1.50mm Pitch, CLIK-Mate Plug Crimp Housing, Single Row, Positive Lock, 2 Circuits, Blue

**Documents:**

<a href="#">3D Model</a>	<a href="#">Product Specification 5025781002-PS-000 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Product Specification 5025781003-PS-000 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Product Specification 5025781004-PS-000 (PDF)</a>
<a href="#">Product Specification 5025780000-PS-000 (PDF)</a>	<a href="#">Application Specification AS-502578-001-001 (PDF)</a>
<a href="#">Product Specification 5025780001-PS-000 (PDF)</a>	<a href="#">Application Specification AS-503395-001-001 (PDF)</a>
<a href="#">Product Specification 5025780002-PS-000 (PDF)</a>	<a href="#">Packaging Specification SPK-502578-001-001 (PDF)</a>
<a href="#">Product Specification 5025780003-PS-000 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification 5025781000-PS-000 (PDF)</a>	

**Agency Certification**

UL E29179

**General**

Product Family Crimp Housings  
 Series [502578](#)  
 Application Signal, Wire-to-Board  
 Overview [CLIK-Mate Wire-to-Board Connectors](#)  
 Product Name CLIK-Mate  
 UPC 800756699868


**Physical**

Circuits (maximum) 2  
 Color - Resin Blue  
 Flammability SC-0  
 Gender Plug  
 Glow-Wire Capable No  
 Keying to Mating Part None  
 Lock to Mating Part Yes  
 Material - Resin PBT  
 Net Weight 187.300/mg  
 Number of Rows 1  
 Packaging Type Bag  
 Panel Mount No  
 Pitch - Mating Interface 1.50mm  
 Pitch - Termination Interface 1.50mm  
 Polarized to Mating Part Yes  
 Stackable No  
 Temperature Range - Operating -40° to +105°C

**Material Info**

**Reference - Drawing Numbers**

Application Specification AS-502578-001-001, AS-503395-001-001  
 Packaging Specification SPK-502578-001-001  
 Product Specification 5025780000-PS-000, 5025780001-PS-000, 5025780002-PS-000, 5025780003-PS-000, 5025781000-PS-000, 5025781002-PS-000, 5025781003-PS-000, 5025781004-PS-000  
 Sales Drawing 5025780000-SD-000

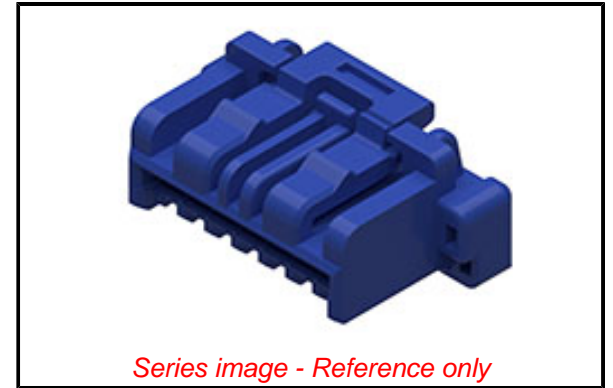

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 D(2020)9139-DC (19  
 Jan 2021)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[502578](#) Series

**Mates With**

CLIK-Mate Bottom-Entry Receptacle [503395](#)  
 . CLIK-Mate Right Angle Receptacles  
[503175](#) , [502585](#) , [213226](#) . CLIK-Mate  
 Vertical Receptacles [503159](#) , [502584](#) ,  
[213225](#)

**Use With**

CLIK-Mate Tin Terminals [502579](#) , [503429](#)  
 <br> CLIK-Mate Gold Terminals [213028](#) ,  
[213029](#) <br> CLIK-Mate Pre-Crimped Lead  
[797581011](#) , [215710](#) , [215711](#)

This document was generated on 03/10/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**