


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **5054731010**
Status: **Active**
Overview: SlimStack Board-to-Board Connectors
Description: SlimStack Board-to-Board Connector, 0.40mm Pitch, Battery Series, Receptacle, 0.60mm Mated Height, 2.00mm Mated Width, 10 Circuits, 10.0A

Documents:

3D Model	Packaging Specification 5054739200-200 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification 5054730000-000 (PDF)	Product Literature (PDF)
Application Specification 5054730000-A00 (PDF)	Product Literature (PDF)

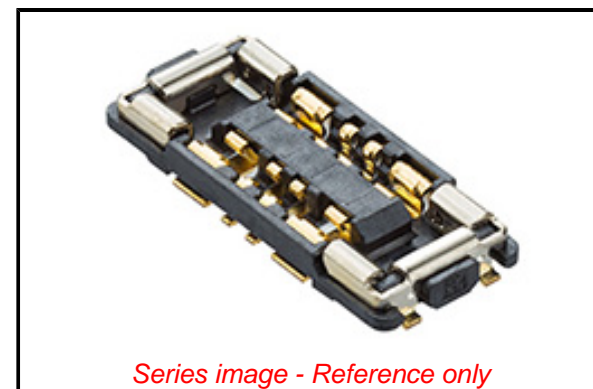

General

Product Family	PCB Receptacles
Series	505473
Application	Board-to-Board
Comments	* 10A of current per circuit is applicable if the circuit was constructed by two power pins via a PWB/FPC circuit, * 10A of current per circuit is applicable if the circuit was constructed by two power pins via a PWB/FPC circuit
Datasheet Order No	987651-2484, 987651-8794_ZH, 987651-8796_DE, 987651-8797_JA, 987651-8798_KO, 987651-8799_ES
Overview	SlimStack Board-to-Board Connectors
Product Guide Order No	987651-8281
Product Literature Order No	987652-0196, Reference Guide#
Product Name	SlimStack
Series Name	Battery
UPC	889056268882

Physical

(p)ower-(s)ignal Configuration	4p - 6s
Circuits (Loaded)	10
Circuits (maximum)	10
Color - Resin	Black
Durability (mating cycles max)	10
Glow-Wire Capable	No
Lock to Mating Part	Yes
Mated Height	0.60mm
Mated Width	2.00mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold over Nickel
Material - Plating Termination	Gold over Nickel
Material - Resin	Liquid Crystal Polymer
Net Weight	0.026/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.40mm
Polarized to Mating Part	No
Polarized to PCB	No
Temperature Range - Operating	-40° to +85°C
Termination Interface: Style	Surface Mount

Electrical

Current - Maximum per Contact	0.5A, 5.0A*
-------------------------------	-------------

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/88/2018 (15
January 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

505473 Series

Mates With

SlimStack Battery (10.0A) Plug [505476](#)

Voltage - Maximum

50V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Application Specification

5054730000-A00

Packaging Specification

5054739200-200

Product Specification

5054730000-000

Sales Drawing

5054730000-000, 5054731000-000

This document was generated on 04/25/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION