

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0190670032**
Status: **Active**
Overview: Solderless Terminals
Description: NylaKrimp™ Funnel Entry Ring Tongue Terminal for 8 AWG Wire, Stud Size 1/2" (M12)

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-016-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-013-001 \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Ring and Spade Terminals
 Series 19067
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview Solderless Terminals
 Product Name NylaKrimp™
 Type Ring
 UPC 800753065697

Physical


Barrel Type Closed - Brazed
 Flammability 94V-2
 Insulation Nylon (PA)
 Material - Plating Mating Tin
 Net Weight 18.004/g
 Packaging Type Bag
 Plating min - Mating 2.540µm
 Plating min - Termination 2.540µm
 Stud Size 1/2" (M12)
 Termination Interface: Style Crimp or Compression
 Wire Insulation Diameter 8.98mm max.
 Wire Size AWG 8

Material Info

Engineering Number D-953-12

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001,
 PS-19902-016-001
 Sales Drawing SD-19067-017

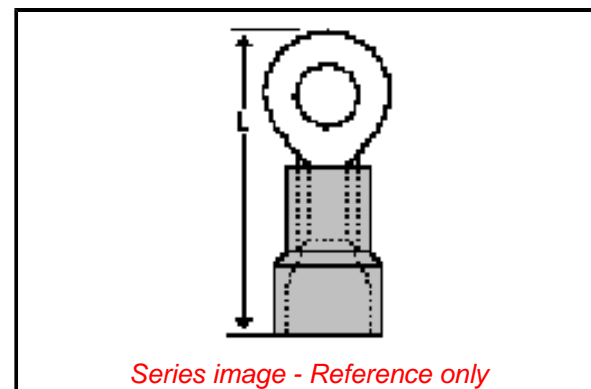

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/21/2016 (20 June
 2016)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19067 Series