

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0190980074**
Status: **Active**
Overview: Solderless Terminals
Description: Krimptite™ Snap Spade Terminal, for 10-12 AWG Wire, Stud Size 10 (M5), 19.60mm Length

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Ring and Spade Terminals
 Series 19098
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview Solderless Terminals
 Product Name Krimptite™
 Type Spade Snap
 UPC 800755081596

Physical

Barrel Type Closed
 Insulation None
 Material - Plating Mating Tin
 Net Weight 1.282/g
 Packaging Type Bag
 Stud Size 10 (M5)
 Wire Size AWG 10, 12
 Wire Size mm² 3.30-5.00

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number C-1719-10

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001
 Sales Drawing CCD10503

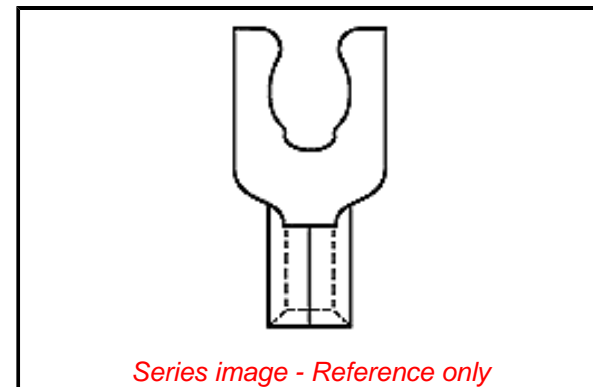

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19098 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION