

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0192000001](#)  
**Status:** **Active**  
**Overview:** [Splices](#)  
**Description:** Avikrimp™ Seamless Butt Splice for 14-16 AWG Wire, Super Duty

**Documents:**

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)  
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

UL E32244

**General**

Product Family [Splices](#)  
 Series [19200](#)  
 Comments [Blue](#)  
 Crimp Quality Equipment [Yes](#)  
 Mil-Spec [N/A](#)  
 Overview [Splices](#)  
 Product Name [Avikrimp™](#)  
 UPC [756054238622](#)

**Physical**

Barrel Type [Closed](#)  
 Color - Resin [Blue](#)  
 Flammability [94V-2](#)  
 Insulation [Nylon \(PA\)](#)  
 Material - Metal [Copper](#)  
 Material - Plating Mating [Tin](#)  
 Material - Plating Termination [Tin](#)  
 Net Weight [1.983/g](#)  
 Packaging Type [Bag](#)  
 Temperature Range - Operating [105°C](#)  
 Wire Insulation Diameter [4.29mm](#)  
 Wire Size AWG [14, 16](#)

**Electrical**


Voltage - Maximum [600V](#)

**Material Info**

Engineering Number [BS-831](#)

**Reference - Drawing Numbers**

Product Specification [PS-19902-011-001, PS-19902-013-001](#)  
 Sales Drawing [SD-19200-001](#)

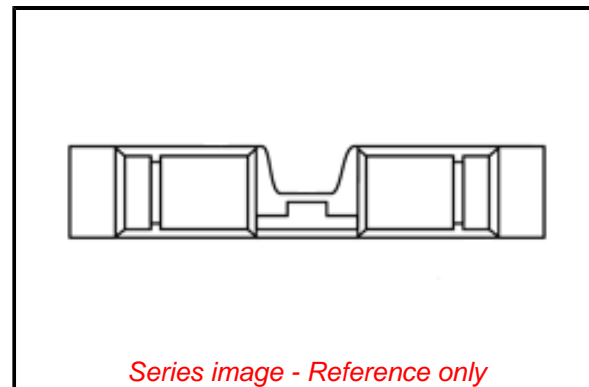

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 ED/108/2014 (17 Dec  
 2014)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product  
 environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any  
 non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

**Search Parts in this Series**

[19200 Series](#)