

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0350230003**  
**Status:** **Active**  
**Description:** 2.00mm Pitch Board-in Crimp Housing, 3 Circuits

**Documents:**

[3D Model](#) [Packaging Specification PK-35023-001-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-35023-001-001 \(PDF\)](#)

**Agency Certification**

CSA LR19980  
 UL E29179

**General**

Product Family Crimp Housings  
 Series [35023](#)  
 Application Signal  
 Product Name Board-In  
 UPC 800753750845

**Physical**

Circuits (maximum) 3  
 Color - Resin Natural  
 Flammability 94V-0  
 Gender Receptacle  
 Glow-Wire Compliant No  
 Material - Resin Nylon  
 Net Weight 0.073/g  
 Number of Rows 1  
 Packaging Type Bag  
 Panel Mount No  
 Pitch - Mating Interface 2.00mm  
 Stackable No  
 Temperature Range - Operating -40°C to +105°C


**Solder Process Data**

Lead-freeProcess Capability N/A

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification PK-35023-001-001  
 Product Specification PS-35023-001-001  
 Sales Drawing SD-35023-001

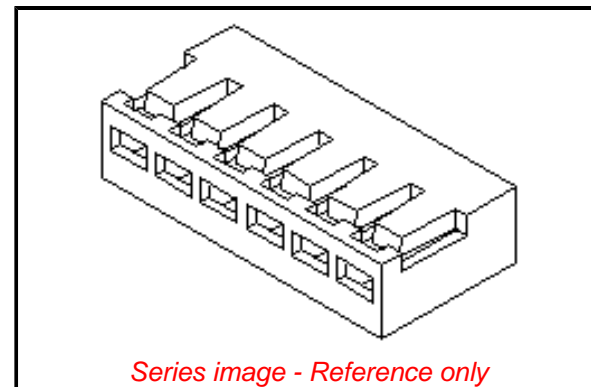

**EU ELV**

**Compliant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 ED/30/2017 (7 July  
 2017)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product  
 environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any  
 non-product compliance questions.

China ROHS	Green Image
ELV	Compliant
RoHS Phthalates	Not Contained

**Search Parts in this Series**

[35023 Series](#)

**Use With**

Straight Terminal [35044-9102](#) , [35044-9260](#)  
 <br>Right Angle Terminal [35021-1201](#) ,  
[35021-1301](#) , [35021-1360](#)