

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0733660061](#)
Status: **Active**
Overview: MCX RF Connectors
Description: 50 Ohms, MCX Jack Receptacle, Vertical, Straight, 7.10mm Height, 1.57mm Standoff Height, Gold (Au) Plated Body, Tray

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General

Product Family	RF/Coax Connectors
Series	73366
Overview	<u>MCX RF Connectors</u>
Product Name	MCX
Style	PCB
UPC	800756205649
Wire/Cable Type	N/A

Physical

Gender	Jack
Keying to Mating Part	None
Net Weight	0.560/g
Orientation	Straight
PCB Mounting	Through Hole
PCB Thickness - Recommended	1.20mm
Packaging Type	Tray
Panel Mount	No
Panel Mount Method	N/A
Reverse Polar	No

Electrical

Impedance	50Ω
-----------	-----


Solder Process Data

Duration at Max. Process Temperature (seconds)	010
Lead-free Process Capability	REFLOW
Max. Cycles at Max. Process Temperature	002
Process Temperature max. C	260

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-73366-006, SD-73366-619-000
---------------	--------------------------------

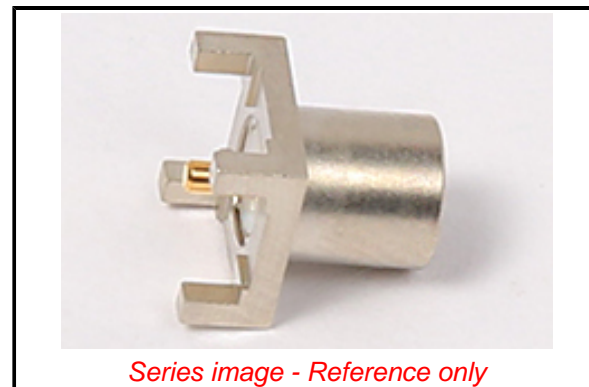

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[73366 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION