

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0192740005**
Status: **Active**
Overview: Quixon™ Terminals
Description: Quixon Quick Disconnect, InsulKrimp™ Style, Female, Partially Insulated Blue, 14-16 AWG, Loose

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E79133

General

Product Family Quick Disconnects
 Series 19274
 Comments Low Insertion Force
 Crimp Quality Equipment Yes
 Insulated Partial
 Overview Quixon™ Terminals
 Product Name InsulKrimp™, Quixon
 Type Quick Disconnect
 UPC 884982564992

Physical

Barrel Type Closed
 Color - Resin Blue
 Flammability 94V-0
 Gender Female
 Glow-Wire Compliant No
 Insulation PVC
 Lock to Mating Part None
 Material - Metal Brass
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Net Weight 0.771/g
 Orientation Straight
 Packaging Type Bag
 Tab Thickness 0.41mm
 Tab Width 7.87mm
 Temperature Range - Operating -55°C to +105°C
 Wire Insulation Diameter 3.50mm
 Wire Size AWG 14, 16

Electrical


Voltage - Maximum 600V

Material Info

Engineering Number BB-2141-LIF

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001
 Sales Drawing SD-19274-001

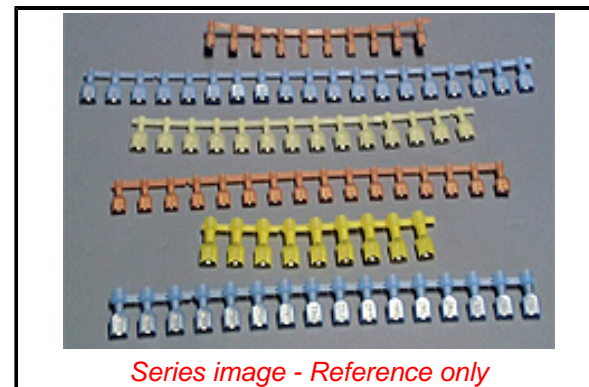

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Contained Per -
 ED/30/2017 (7 July
 2017)
 2,4-Di-tert-butyl-6-(5-
 chlorobenzotriazol-2-
 yl)p

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[19274 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION