

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0393800102](#)  
**Status:** **Active**  
**Overview:** Eurostyle™ Terminal Blocks  
**Description:** 6.35mm Pitch Beau Eurostyle Fixed Mount PCB Terminal Block, Modular, 2 Circuits

**Documents:**

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Drawing \(PDF\)](#)

**General**

Product Family	Terminal Blocks
Series	<a href="#">39380</a>
Application	N/A
Component Type	One Piece
Overview	<a href="#">Eurostyle™ Terminal Blocks</a>
Product Name	Eurostyle™ Fixed Mount
Type	Euro Block
UPC	822348022977

**Physical**

Circuits (Loaded)	2
Color - Resin	Black
Entry Angle	Horizontal
Lock to Mating Part	None
Material - Resin	Nylon
Number of Rows	1
Orientation	Vertical
PC Tail Length	5.20mm
PCB Retention	None
PCB Thickness - Recommended	4.00mm
Panel Mount	No
Pitch - Mating Interface	6.35mm
Pitch - Termination Interface	6.35mm
Polarized to Mating Part	N/A
Shrouded	Fully
Stackable	Yes
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	110°C
Wire Size AWG	10, 12, 14, 16, 18, 20, 22, 24, 26, 28, 30
Wire Size mm²	0.05-2.50

**Electrical**


Current - Maximum per Contact	30.0A
Voltage - Maximum	300V

**Material Info**

Engineering Number	MX-MSP0200S-0N
--------------------	----------------

**Reference - Drawing Numbers**

Sales Drawing	SD-39380-001
---------------	--------------

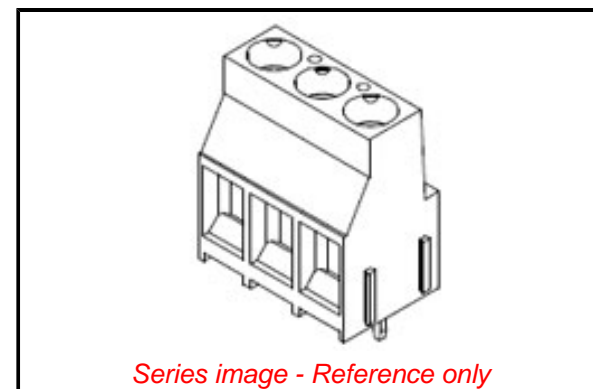

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per - ED/108/2014 (17 Dec 2014)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

**Search Parts in this Series**

[39380 Series](#)