

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0393710003](#)
Status: **Active**
Overview: Eurostyle™ Terminal Blocks
Description: 7.50mm Beau Eurostyle Pluggable PCB Terminal Block, 180° Wire Entry, 3 Circuits

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family Terminal Blocks
 Series [39371](#)
 Application N/A
 Component Type Plug
 Overview [Eurostyle™ Terminal Blocks](#)
 Product Name Eurostyle™ Pluggable
 Type Euro Block
 UPC 822348040179

Physical

Circuits (Loaded) 3
 Entry Angle 180° Angle
 Flammability 94V-0
 Lock to Mating Part None
 Number of Rows 1
 Orientation Right Angle
 PCB Retention N/A
 Panel Mount No
 Pitch - Mating Interface 7.50mm
 Pitch - Termination Interface 7.50mm
 Polarized to Mating Part Yes
 Stackable Yes
 Temperature Range - Operating 110°C
 Wire Size AWG 12, 14, 16, 18, 20, 22, 24, 26, 28, 30
 Wire Size mm² 0.05-2.50

Electrical


Current - Maximum per Contact 15.0A
 Voltage - Maximum 300V

Material Info

Engineering Number MX-CIF03003-0N

Reference - Drawing Numbers

Sales Drawing SD-39371-001

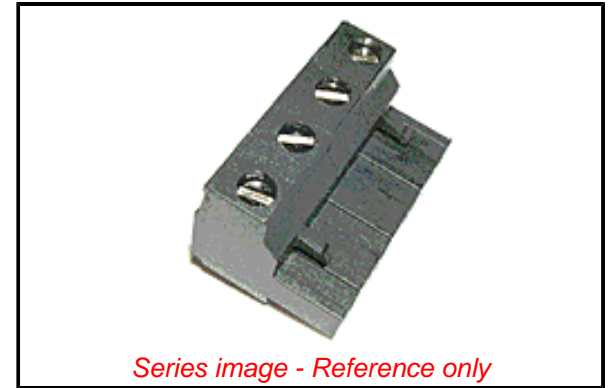

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[39371](#) Series

Mates With

[39372](#) , [39373](#) Headers