

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0387406113](#)
Status: **Active**
Overview: Beau™ Barrier Strips
Description: 11.11mm Pitch Beau PCB Fixed Mount Barrier Terminal Strip, Low Profile, 300V, 13 Circuits

Documents:

[3D Model](#) [Product Specification PS-38730-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Terminal Blocks
Series	38740
Application	N/A
Component Type	One Piece
Overview	Beau™ Barrier Strips
Product Name	Fixed Mount Barrier
Type	Barrier Strip
UPC	800756319759

Physical

Circuits (Loaded)	13
Circuits (maximum)	13
Color - Resin	Black
Entry Angle	Horizontal
Lock to Mating Part	No
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester Alloy
Number of Rows	1
Orientation	Horizontal
PC Tail Length	5.50mm
PCB Retention	Yes
PCB Thickness - Recommended	2.40mm
Panel Mount	No
Pitch - Mating Interface	11.11mm
Pitch - Termination Interface	11.11mm
Polarized to Mating Part	No
Stackable	No
Temperature Range - Operating	-40°C to +130°C
Wire Size AWG	14, 16, 18, 20, 22
Wire Size mm²	0.50-1.50

Electrical


Current - Maximum per Contact	15.0A
Voltage - Maximum	300V

Material Info

Engineering Number	74513
--------------------	-------

Reference - Drawing Numbers

Product Specification	PS-38730-001-001
Sales Drawing	SD-38740-002

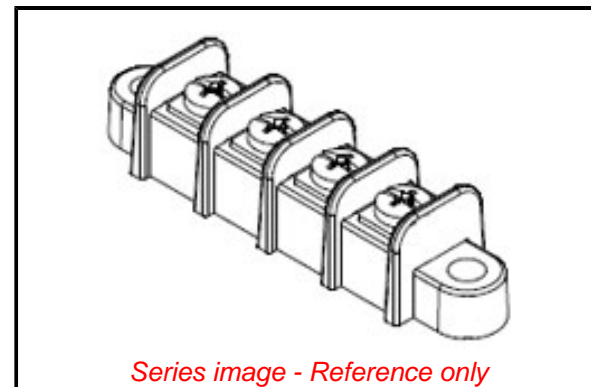

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[38740 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION