

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0395045607](#)
Status: **Active**
Overview: Eurostyle™ Terminal Blocks
Description: 3.50mm Pitch Eurostyle Horizontal Plug, with Retention Screws and Standard Imprinting, Green Housing, Gold (Au) Plated, 7 Circuits

Documents:

[3D Model](#) [Product Specification PS-39500-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family Terminal Blocks
 Series [39504](#)
 Application N/A
 Comments with Standard Imprinting
 Component Type Plug
 Overview [Eurostyle™ Terminal Blocks](#)
 Product Name ESE, Eurostyle™ Pluggable
 Type Euro Block
 UPC 822350444583

Physical

Circuits (Loaded) 7
 Entry Angle Vertical
 Lock to Mating Part Yes
 Number of Rows 1
 Orientation Horizontal
 Panel Mount No
 Pitch - Mating Interface 3.50mm
 Pitch - Termination Interface 3.50mm
 Polarized to Mating Part Yes
 Stackable No
 Temperature Range - Operating -40°C to +105°C
 Wire Size AWG 16, 18, 20, 22, 24, 26, 28, 30
 Wire Size mm² 0.05-1.31


Electrical

Current - Maximum per Contact 8.0A
 Voltage - Maximum 300V

Material Info

Reference - Drawing Numbers

Product Specification PS-39500-001-001
 Sales Drawing SD-39504-001

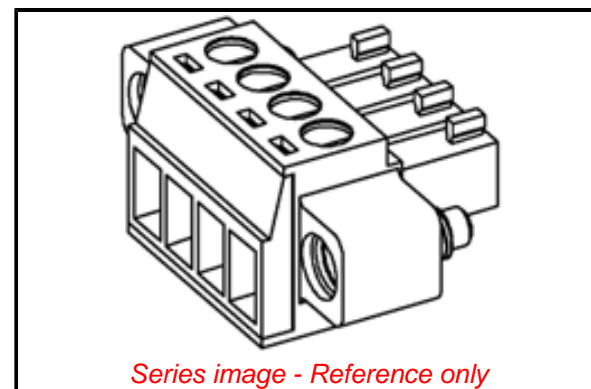

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[39504 Series](#)

Mates With

Most 3.50mm Pitch Industry Standard PCB Headers, [39505 Vertical PCB Header with Threaded Retention Inserts](#), [39506 Horizontal PCB Header with Threaded Retention Inserts](#)