

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395431205

Status:


Active

Overview:

Eurostyle™ Terminal Blocks

Description:

5.00mm Pitch Eurostyle 45° Wire Entry Fixed Mount PCB Terminal Block, with Screw Pressure Clamp, with Standard Imprinting, 5 Circuits

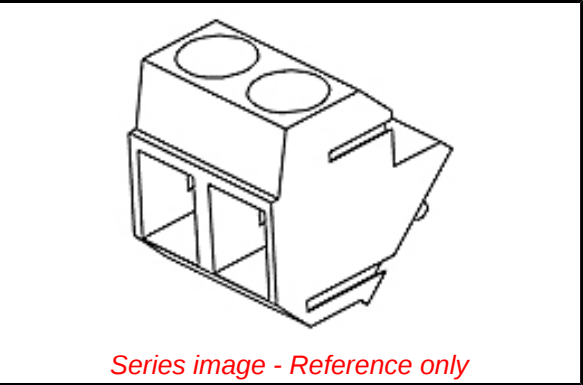

Documents:

3D Model

RoHS Certificate of Compliance (PDF)

Drawing (PDF)

Agency Certification	
UL	E48521
General	
Product Family	Terminal Blocks
Series	39543
Application	N/A
Comments	with Standard Imprinting
Component Type	One Piece
Overview	Eurostyle™ Terminal Blocks
Product Name	ESE, Eurostyle™ Fixed Mount
Type	Euro Block
UPC	822350539104
Physical	
Circuits (Loaded)	5
Entry Angle	45° Angle
Lock to Mating Part	None
Number of Rows	1
Orientation	45° Angle
PC Tail Length	3.00mm
PCB Thickness - Recommended	2.00mm
Panel Mount	No
Pitch - Mating Interface	5.00mm
Pitch - Termination Interface	5.00mm
Polarized to Mating Part	N/A
Stackable	No
Temperature Range - Operating	-40°C to +105°C
Wire Size AWG	14, 16, 18, 20, 22, 24
Wire Size mm²	0.20-2.08
Electrical	
Current - Maximum per Contact	10.0A
Voltage - Maximum	300V
Solder Process Data	
Duration at Max. Process Temperature (seconds)	005
Lead-freeProcess Capability	WAVE
Max. Cycles at Max. Process Temperature	135
Process Temperature max. C	260
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-39543-001

EU ELV

Not Relevant

EU RoHS

Not Reviewed

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

39543 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION