

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [10-11-2173](#)
Status: **Active**
Overview: [KK® Interconnection System](#)
Description: 2.54mm Pitch KK® Crimp Terminal Housing, High Pressure, 17 Circuits

Documents:

[3D Model](#) [Packaging Specification PK-7880-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-7879 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [7880](#)
 Application Signal, Wire-to-Board
 Overview [KK® Interconnection System](#)
 Product Name KK®
 UPC 800753824447

Physical

Circuits (maximum) 17
 Color - Resin Natural (White)
 Flammability 94V-0
 Gender Female
 Glow-Wire Compliant No
 Material - Resin Nylon
 Net Weight 1.666/g
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 2.54mm
 Stackable No
 Temperature Range - Operating 0°C to +75°C

Material Info

Old Part Number 7880-17B

Reference - Drawing Numbers

Packaging Specification PK-7880-001
 Product Specification PS-7879
 Sales Drawing SD-7880

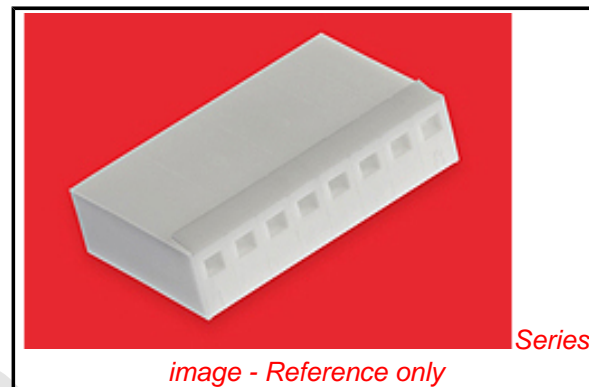


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

7880Series

Mates With

2.54mm pitch KK® PCB Headers

Use With

7879 KK® High Pressure Crimp Terminal