


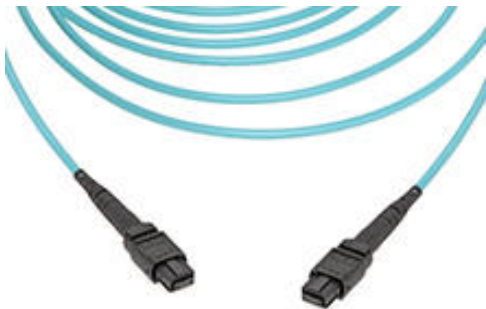

Part Number : [1062250023](#)
Product Description : MPO Female-to-MPO Female
Fiber Optic Trunk Cable Assembly, 9/125µm, 5.40mm,
Singlemode, 12 Fiber, Plenum, OS2, 50.0m Length,
Yellow Cable
Series Number : 106225
Status : Active
Product Category : Fiber Optic Cable Assemblies



Documents & Resources

Drawings
[1062250023_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)4144-DC (27 June 2024)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Fiber Optic Cable Assemblies
Series	106225
Description	MPO Female-to-MPO Female Fiber Optic Trunk Cable Assembly, 9/125µm, 5.40mm, Singlemode, 12 Fiber, Plenum, OS2, 50.0m Length, Yellow Cable
Connector to Connector	MPO-to-MPO
Mode	Singlemode
Product Name	MPO
UPC	191128250351

Physical

Boot Type	Straight
Cable Length	50.0m
Cable Size	5.40mm
Fiber (Core/Cladding)	9/125µm
Net Weight	1704.600/g
Single Ended	No
Wire/Cable Type	12 Fiber OS2 Plenum