




**Part Number :** [150320621](#)

**Product Description :** 0.30mm Pitch Premo-Flex FFC Jumper with Latching Ears, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 21 Circuits

**Series Number :** 15032

**Status :** Active

**Product Category :** Flat-Flexible Cable (FFC)

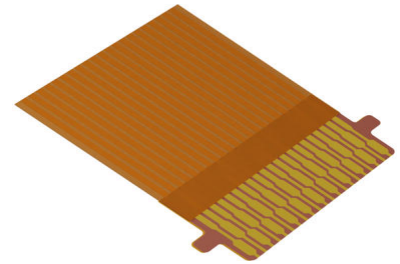

---

## Documents and Resources

### Drawings

[150320621\\_sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

### Specifications

[150320001-000.pdf](#)

---

## Product Environment Compliance

### Compliance

|                    |                                                                                                         |
|--------------------|---------------------------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                                            |
| China RoHS         |  per SJ/T 11365-2006 |
| EU ELV             | Not Relevant                                                                                            |
| Low-Halogen Status | Low-Halogen per IEC 61249-2-21                                                                          |
| REACH SVHC         | Not Contained per D(2025)4165-DC (25 June 2025)                                                         |
| EU RoHS            | Compliant per EU 2015/863                                                                               |

### [Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

### [Industry Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

---

**Part Details**

**General**

|              |                                                                                                                                           |
|--------------|-------------------------------------------------------------------------------------------------------------------------------------------|
| Status       | Active                                                                                                                                    |
| Category     | Flat-Flexible Cable (FFC)                                                                                                                 |
| Series       | 15032                                                                                                                                     |
| Description  | 0.30mm Pitch Premo-Flex FFC Jumper with Latching Ears, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 21 Circuits |
| Product Name | Premo-Flex FFC Jumper                                                                                                                     |
| UPC          | 195842789524                                                                                                                              |

**Electrical**

|                               |      |
|-------------------------------|------|
| Current - Maximum per Contact | 0.2A |
| Voltage - Maximum             | N/A  |

**Physical**

|                           |                                     |
|---------------------------|-------------------------------------|
| Cable Length              | 152.00mm                            |
| Circuits (Loaded)         | 21                                  |
| Contact Layout Type       | A (same side)                       |
| Design Feature            | Miniaturization, Superior Retention |
| Material - Plating Mating | Gold                                |
| Net Weight                | 0.194/g                             |
| Packaging Type            | Bag                                 |
| Pitch - Mating Interface  | 0.30mm                              |

|                               |                           |
|-------------------------------|---------------------------|
| Temperature Range - Operating | -40° to +105°C            |
| Termination Style             | FFC Connector             |
| Wire/Cable Type               | Flat Flexible Cable (FFC) |
| Wire Size (AWG)               | N/A                       |

---

## Mates With / Use With

### Mates with Part(s)

| Description                                                                                                            | Part Number       |
|------------------------------------------------------------------------------------------------------------------------|-------------------|
| Easy-On FPC Connector, 0.30mm Pitch, Right-Angle, Bottom Contact, 0.95mm Height, 21 Circuits, Gold over Nickel Plating | <u>5035662102</u> |