




Part Number : [150671016](#)
Series Number : 15067
Status : Active - Proprietary
Product Category : Flat-Flexible Cable (FFC)

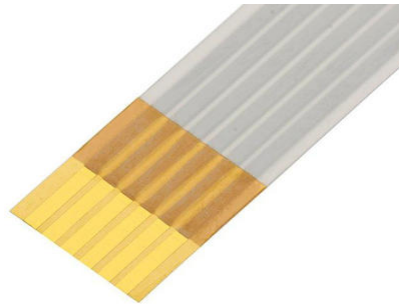

Drawings

[150671016 sd.pdf](#)

Specifications

[150670001-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)6375-DC (05 Nov 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

Part Details

General

Status	Active - Proprietary
Category	Flat-Flexible Cable (FFC)
Series	15067
Description	1.00mm Pitch Premo-Flex Hot Bar Solder FFC Jumpers, Same Side Contacts (Type A), 254.00mm Cable Length, Tin (Sn) Plating, 16 Circuits
Comments	Contacts on the same side, Type A
Product Name	Premo-Flex Hot Bar Solder FFC Jumper
UPC	198282655978

Electrical

Current - Maximum per Contact	1.25A
Voltage - Maximum	60V AC

Physical

Cable Length	254.00mm
Circuits (Loaded)	16
Contact Layout Type	A (same side)
Design Feature	Direct to Board
Material - Plating Mating	Tin
Packaging Type	Bag
Pitch - Mating Interface	1.00mm
Temperature Range - Operating	-40° to +105°C
Termination Style	Solder
Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

This document was generated on Feb 26, 2026