




Part Number : [1729521401](#)
Product Description : Micro-Fit TPA Receptacle
Housing, Dual Row, 14 Circuits, UL 94V-0, Low-
Halogen, Black
Series Number : 172952
Status : Active
Product Category : Connector Housings

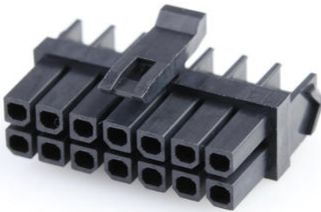

Documents & Resources

Drawings

[1729521401_sd.pdf](#)
[1729520001-PK-000.pdf](#)

3D Models and Design Files

[STEP AP242](#)
[SOLIDWORKS](#)
[Creo](#)

Specifications

[430450001-PS-KO-000.pdf](#)
[430450001-PS-SP-000.pdf](#)
[PS-43045-001.pdf](#)
[430450007-TS-000.pdf](#)
[TS-43045-001-001.pdf](#)
[TS-43045-002-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Relevant
EU ELV	Not Relevant
Low-Halogen Status	Not Relevant
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)

EU RoHS	Compliant per EU 2015/863
---------	---------------------------

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Connector Housings
Series	172952
Description	Micro-Fit TPA Receptacle Housing, Dual Row, 14 Circuits, UL 94V-0, Low-Halogen, Black
Application	Power, Wire-to-Board, Wire-to-Wire
Comments	See Product Specification for maximum current rating by circuit size and wire AWG
Product Name	Micro-Fit TPA
UPC	889056429818

Agency

CSA	LR19980
UL	E29179

Physical

Circuits (maximum)	14
--------------------	----

Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1.001/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

Mates With / Use With

Mates with Part(s)

Description	Part Number
Micro-Fit TPA Dual Row Plug Housings	<u>203632</u>
Micro-Fit 3.0 Dual Row Plug Housings	<u>43020</u>
Micro-Fit 3.0 Dual Row Headers	<u>43045</u>

Use with Part(s)

Description	Part Number
Pre-Crimped Lead Micro-Fit 3.0 Female-to-Micro-Fit 3.0 Female, Tin (Sn) Plating, 150.00mm Length, 20 AWG, Black	<u>797580002</u>
Pre-Crimped Lead Micro-Fit 3.0 Female-to-Micro-Fit 3.0 Female, Gold (Au) Plating, 150.00mm Length, 20 AWG, Black	<u>797580004</u>

Pre-Crimped Lead Micro-Fit 3.0 Female-to-Micro-Fit 3.0 Female, Tin (Sn) Plating, 300.00mm Length, 20 AWG, Black	<u>797580010</u>
Pre-Crimped Lead Micro-Fit 3.0 Female-to-Micro-Fit 3.0 Female, Gold (Au) Plating, 300.00mm Length, 20 AWG, Black	<u>797580012</u>
Micro-Fit Terminal Position Assurance (TPA) Retainers	<u>172953</u>
Micro-Fit 3.0 Female Crimp Terminals	<u>43030</u>
Micro-Fit Reduced Mating Force Female Crimp Terminals	<u>46235</u>