



Part Number : [1731070710](#)


Product Description : FCT Mixed Layout D-Sub Housing, Male, Tin-plated Shell, 5 Circuits Unloaded, Green Insulator

Series Number : 173107

Status : Active

Product Category : D-Sub Connectors

Engineering Part Number : FM5W5P-K121

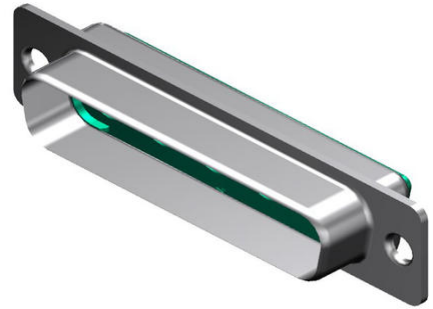

Documents and Resources

Drawings

[1731070710_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Contained per D(2021)10043-DC (17 Jan 2022)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

[EU RoHS Certificate of Compliance](#)

[Additional Product Compliance Information](#)

Part Details

General

Status	Active
Category	D-Sub Connectors
Series	173107
Description	FCT Mixed Layout D-Sub Housing, Male, Tin-plated Shell, 5 Circuits Unloaded, Green Insulator
Magnetic	Yes
Product Name	FCT Products
Type	Mixed Layout
UPC	191130101887

Electrical

Shielded	Yes
----------	-----

Physical

Circuits (Loaded)	0
Circuits (maximum)	5
Color - Resin	Green
Gender	Male
Material - Resin	PBT
Material - Shell	Steel
Net Weight	7.400/g
Number of Rows	1
Packaging Type	Carton
Panel Mount	Front or Rear
Panel Mount Method	Flange
Pitch - Mating Interface	2.84mm
Pitch - Termination Interface	2.54mm
Plating - Shell	Tin

Polarized to Mating Part	Yes
Polarized to PCB	No
Ports	1
Temperature Range - Operating	-55° to +130°C
Waterproof / Dustproof	No

Mates With / Use With

Mates with Part(s)

Description	Part Number
Mates With	FCT Mixed Layout D-Sub, Size 3, 5W5, Socket

Use with Part(s)

Description	Part Number
Use With	FCT Coaxial, High Power, High Voltage, or Pneumatic Contacts