


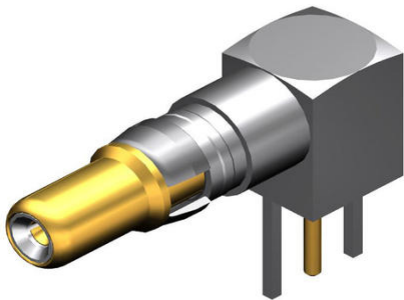

Part Number : [1731121046](#)
Product Description : FCT Coaxial Contact, 3 Pins,
Male, Right-Angle, PCB Through Hole, 50 Ohms,
1.30µm Gold Plating, with Knurl
Series Number : 173112
Status : Obsolete
Product Category : D-Sub Contacts
Engineering Part Number : FME049P108R



Documents and Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Product not active
China RoHS	Product not active
EU ELV	Product not active
Low-Halogen Status	Product not active
REACH SVHC	Product not active
EU RoHS	Product not active

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Obsolete
Category	D-Sub Contacts
Series	173112
Description	FCT Coaxial Contact, 3 Pins, Male, Right-Angle, PCB Through Hole, 50 Ohms, 1.30µm Gold Plating, with Knurl
Contact Type	Coaxial
Magnetic	Yes
Product Name	FCT Products
Type	Mixed Layout
UPC	191130090488

Electrical

Current - Maximum per Contact	2.0A
Impedance	50Ω

Physical

Durability (mating cycles min)	500
Gender	Male
Material - Contact	Copper Alloy
Material - Plating Mating	Gold over Nickel
Material - Plating Termination	Tin over Nickel
Net Weight	3.300/g
Orientation	Right-Angle
Packaging Type	Tube
Plating min - Mating	1.300µm
Plating min - Termination	5.000µm
Temperature Range - Operating	-55° to +135°C
Termination Style	Through Hole

Mates With / Use With

Use with Part(s)

Description	Part Number
Use With	FCT Mixed Layout Connectors

This document was generated on Feb 27, 2026

Obsolete