




Part Number : [173280210](#)

Product Description : 0.50mm Pitch Premo-Flex FFC Jumper with Ears, Same Side Contacts (Type A), 51.00mm Cable Length, Gold (Au) Plating, 10 Circuits

Series Number : 17328

Status : Active

Product Category : Flat-Flexible Cable (FFC)

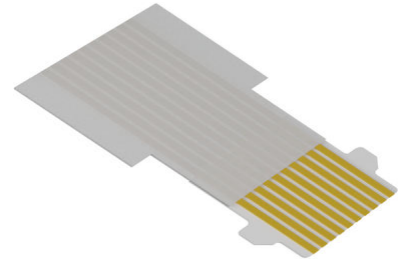

Documents & Resources

Drawings

[173280210 sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)


[Creo](#)

Specifications

[173280001-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Reviewed
China RoHS	per SJ/T 11365-2006 
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

[Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

[Industry Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	17328
Description	0.50mm Pitch Premo-Flex FFC Jumper with Ears, Same Side Contacts (Type A), 51.00mm Cable Length, Gold (Au) Plating, 10 Circuits
Comments	Contacts on the same side, Type A
Product Name	Premo-Flex FFC Jumper
UPC	198282267416

Electrical

Current - Maximum per Contact	0.55A
Voltage - Maximum	60V AC

Physical

Cable Length	51.00mm
Circuits (Loaded)	10
Contact Layout Type	A (same side)
Design Feature	Superior Retention
Material - Plating Mating	Gold
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C

Termination Style	FFC Connector
Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

Mates With / Use With

Mates with Part(s)

Description	Part Number
Mates With	Intermateable with Hirose FH28

This document was generated on Oct 02, 2025