

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1805800101

Status:


Active

Overview:

LED Array Holders, Dual-Ended Wire Trap

Description:

LED Array Holder for 16.00 by 19.00mm COB, Rectangular Version, Gold (Au) Plating, PBT, One-Piece Design, White

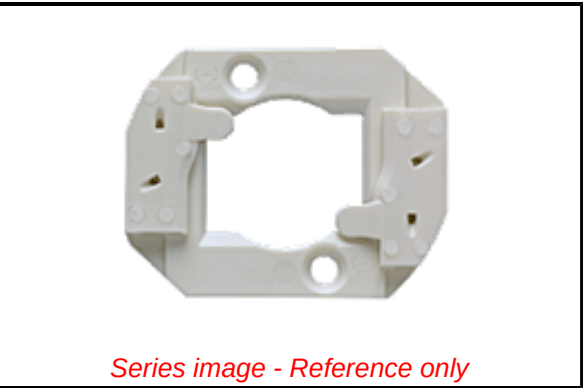

|                                               |                                                   |
|-----------------------------------------------|---------------------------------------------------|
| Documents:                                    |                                                   |
| 3D Model                                      | Application Specification AS-180328-001-001 (PDF) |
| Drawing (PDF)                                 | Packaging Specification PK-180586-001-001 (PDF)   |
| 3D Model (PDF)                                | Test Summary TS-180155-001-001 (PDF)              |
| Product Specification PS-180580-001-001 (PDF) | RoHS Certificate of Compliance (PDF)              |

|                             |                                         |
|-----------------------------|-----------------------------------------|
| Agency Certification        |                                         |
| UL                          | E345583                                 |
| General                     |                                         |
| Product Family              | Solid State Lighting                    |
| Series                      | 180580                                  |
| Array Type                  | Nichia                                  |
| Beam Angle                  | N/A                                     |
| Height                      | 4.10mm                                  |
| Overview                    | LED Array Holders, Dual-Ended Wire Trap |
| Product Name                | Wire Trap Holder                        |
| Type                        | LED COB Array Holder                    |
| UPC                         | 887191653433                            |
| Physical                    |                                         |
| Base Type                   | N/A                                     |
| Color Rendering Index (CRI) | N/A                                     |
| Correlated Color Temp (CCT) | N/A                                     |
| Depth                       | 0.90mm                                  |
| Flammability                | 94V-0                                   |
| Lamp Type                   | N/A                                     |
| Material - Metal            | Copper Alloy                            |
| Mounting Style              | Screws                                  |
| Net Weight                  | 8.868/g                                 |
| Packaging Type              | Tray                                    |
| Electrical                  |                                         |
| Lamp Wattage - Maximum      | N/A                                     |
| Lumens                      | N/A                                     |
| Voltage (Fixture) - Maximum | 600V DC                                 |
| Wiring Style                | Poke In Wire Traps                      |
| Material Info               |                                         |
| Reference - Drawing Numbers |                                         |
| Application Specification   | AS-180328-001-001                       |
| Packaging Specification     | PK-180586-001-001                       |
| Product Specification       | PS-180580-001-001                       |
| Sales Drawing               | SD-180580-001                           |
| Test Summary                | TS-180155-001-001                       |

|                                                               |               |
|---------------------------------------------------------------|---------------|
| EU ELV                                                        |               |
| Not Relevant                                                  |               |
| EU RoHS                                                       | China RoHS    |
| Compliant                                                     |               |
| REACH SVHC                                                    |               |
| Not Contained Per - ECHA_01_2020 (16 January 2020)            |               |
| Halogen-Free                                                  |               |
| Status                                                        |               |
| Not Low-Halogen                                               |               |
| For more information, please visit <a href="#">Contact US</a> |               |
| China ROHS                                                    | Green Image   |
| ELV                                                           | Not Relevant  |
| RoHS Phthalates                                               | Not Contained |

Search Parts in this Series

180580 Series

Use With

19.00mm by 16.00mm COB

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION