


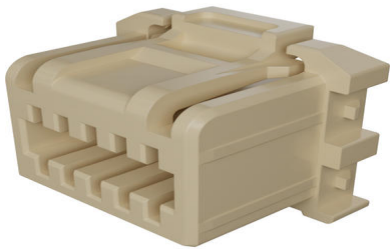

Part Number : [2145271000](#)
Product Description : Micro-Lock Plus TPA Type
Receptacle Housing, 1.25mm Pitch, Low-Halogen, Dual
Row, Positive Lock, 10 Circuits, Natural (White)
Series Number : 214527
Status : Active
Product Category : Connector Housings



Documents and Resources

Drawings

[2145271000_sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[2145271000.dxf](#)

Specifications

[5054320000-AS-000.pdf](#)

[2145279200-SPK-200.pdf](#)

[2145270000-PS-000.pdf](#)

[2145270001-PS-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)6375-DC (05 Nov 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Connector Housings
Series	214527
Description	Micro-Lock Plus TPA Type Receptacle Housing, 1.25mm Pitch, Low-Halogen, Dual Row, Positive Lock, 10 Circuits, Natural (White)
Application	Wire-to-Board, Wire-to-Wire
Product Name	Micro-Lock Plus
UPC	193264680115

Agency

UL	E29179
----	--------

Physical

Circuits (maximum)	10
Color - Resin	Natural (White)
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None

Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	264.990/mg
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.25mm
Pitch - Termination Interface	1.25mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C

Mates With / Use With

Mates with Part(s)

Description	Part Number
1.25mm Pitch Micro-Lock Plus Vertical, Dual Row, Surface Mount Headers	<u>505433</u>
1.25mm Pitch Micro-Lock Plus Right-Angle, Dual Row, Surface Mount Headers	<u>505448</u>
1.25mm Pitch Micro-Lock Plus Right-Angle, Dual Row, Surface Mount Headers	<u>204519</u>
1.25mm Pitch Micro-Lock Plus Vertical, Dual Row, Surface Mount Headers	<u>204520</u>
1.25mm Pitch Micro-Lock Plus Vertical, Dual Row, Surface Mount Headers with Potting Capability	<u>207760</u>

Use with Part(s)

Description	Part Number
Micro-Lock Plus Female Crimp Terminal, 1.25mm Pitch, Matte Tin (Sn) Plating, 30-26 AWG, Reel	<u>5054311000</u>
1.25mm Pitch Micro-Lock Plus TPA Retainers	<u>214528</u>

1.25mm Pitch Micro-Lock Plus Female Crimp Terminals	<u>214529</u>
--	---------------