



Part Number : [387406125](#)


Product Description : 11.11mm Pitch Beau PCB
Fixed Mount Barrier Terminal Strip, Low Profile, 300V,
25 Circuits

Series Number : 38740

Status : Obsolete

Product Category : Terminal Blocks and Barrier
Strip

Engineering Part Number : 74525

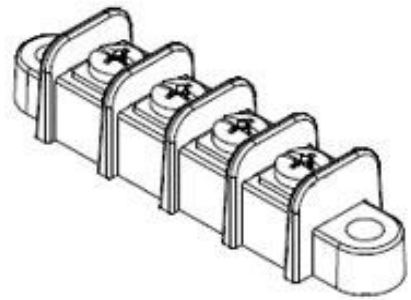

Documents and Resources

Drawings

[387406125_sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Specifications

[PS-38730-001-001.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Obsolete
Category	Terminal Blocks and Barrier Strip
Series	38740
Description	11.11mm Pitch Beau PCB Fixed Mount Barrier Terminal Strip, Low Profile, 300V, 25 Circuits
Application	Wire-to-Board
Component Type	One Piece
Product Name	Fixed Mount Barrier
Type	Barrier Strips
UPC	822348120338

Electrical

Current - Maximum per Contact	15.0A
Voltage - Maximum	300V

Physical

Circuits (Loaded)	25
Circuits (maximum)	25
Color - Resin	Black
Entry Angle	Horizontal
Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Tin

Material - Plating Termination	Tin
Material - Resin	Polyester Alloy
Number of Rows	1
Orientation	Horizontal
Panel Mount	No
PCB Retention	Yes
PCB Thickness - Recommended	2.40mm
PC Tail Length	5.50mm
Pitch - Mating Interface	N/A
Pitch - Termination Interface	11.11mm
Polarized to Mating Part	No
Stackable	No
Temperature Range - Operating	-40° to +130°C
Wire Size (AWG)	14, 16, 18, 20, 22
Wire Size mm ²	0.33-2.08

This document was generated on Feb 26, 2026