




**Part Number :** [395332312](#)  
**Product Description :** 5.08mm Pitch Eurostyle  
Vertical Plug, with Standard Imprinting, Rear Wire  
Entry, Black, 12 Circuits  
**Series Number :** 39533  
**Status :** Active  
**Product Category :** Terminal Blocks and Barrier  
Strip

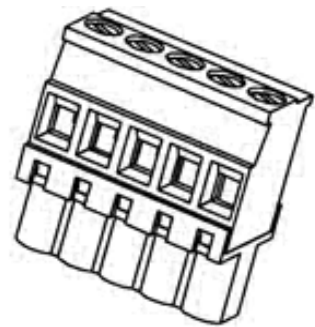

---

## Documents and Resources

### Drawings

[395332312 sd.pdf](#)

### 3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

### Specifications

[PS-39500-001-001.pdf](#)

---

## Product Environment Compliance

### Compliance

|                    |                                               |
|--------------------|-----------------------------------------------|
| GADSL/IMDS         | Not Relevant                                  |
| China RoHS         | Not Reviewed per SJ/T 11365-2006              |
| EU ELV             | Not Relevant                                  |
| Low-Halogen Status | Not Reviewed per IEC 61249-2-21               |
| REACH SVHC         | Not Reviewed per D(2025)7771-DC (04 Feb 2026) |
| EU RoHS            | Not Reviewed per EU 2015/863                  |

### Compliance Statements

- EU RoHS
- REACH SVHC

- Low-Halogen

#### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

#### Substances of Interest

- PFAS

#### EU RoHS Certificate of Compliance

#### Additional Product Compliance Information

---

## Part Details

### General

|                |                                                                                                     |
|----------------|-----------------------------------------------------------------------------------------------------|
| Status         | Active                                                                                              |
| Category       | Terminal Blocks and Barrier Strip                                                                   |
| Series         | 39533                                                                                               |
| Description    | 5.08mm Pitch Eurostyle Vertical Plug, with Standard Imprinting, Rear Wire Entry, Black, 12 Circuits |
| Application    | Wire-to-Board                                                                                       |
| Comments       | Rear Wire Entry, with Standard Imprinting                                                           |
| Component Type | Plug                                                                                                |
| Product Name   | Eurostyle Pluggable                                                                                 |
| Type           | PCB Terminal Blocks and Connectors                                                                  |
| UPC            | 822350523868                                                                                        |

### Agency

|    |        |
|----|--------|
| UL | E48521 |
|----|--------|

### Electrical

|                               |       |
|-------------------------------|-------|
| Current - Maximum per Contact | 18.0A |
| Voltage - Maximum             | 300V  |

### Physical

|                               |                                |
|-------------------------------|--------------------------------|
| Circuits (Loaded)             | 12                             |
| Color - Resin                 | Black                          |
| Entry Angle                   | Horizontal                     |
| Lock to Mating Part           | Yes                            |
| Number of Rows                | 1                              |
| Orientation                   | N/A                            |
| Panel Mount                   | No                             |
| PCB Retention                 | N/A                            |
| Pitch - Mating Interface      | 5.08mm                         |
| Pitch - Termination Interface | 5.08mm                         |
| Polarized to Mating Part      | Yes                            |
| Stackable                     | No                             |
| Temperature Range - Operating | -40° to +105°C                 |
| Wire Size (AWG)               | 12, 14, 16, 18, 20, 22, 24, 26 |
| Wire Size mm <sup>2</sup>     | 0.13-3.31                      |

#### Solder Process Data

|                              |     |
|------------------------------|-----|
| Lead-Free Process Capability | N/A |
|------------------------------|-----|

---

#### Mates With / Use With

##### Mates with Part(s)

| Description                                   | Part Number                                     |
|-----------------------------------------------|-------------------------------------------------|
| 5.08mm Pitch Eurostyle Vertical PCB Headers   | <a href="#"><u>39531</u></a>                    |
| 5.08mm Pitch Eurostyle Horizontal PCB Headers | <a href="#"><u>39532</u></a>                    |
| 5.08mm Pitch Eurostyle Dual Level PCB Headers | <a href="#"><u>39538</u></a>                    |
| Mates With                                    | Most 5.08mm Pitch Industry Standard PCB Headers |