


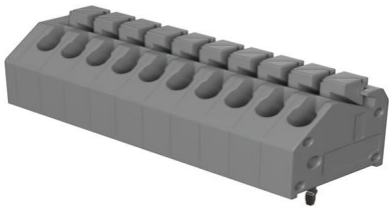

Part Number : [397000710](#)
Product Description : 3.50mm Pitch, Eurostyle
Fixed-Mount Push-Button Terminal Block, 45°
Modular, 5A, 20-16 AWG, Light Gray, 10 Circuits
Series Number : 39700
Status : Active
Product Category : Terminal Blocks and Barrier
Strip
Engineering Part Number : M710-02-10-9



Documents and Resources

Drawings

[397000710_sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Reviewed per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Not Reviewed per EU 2015/863

[Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Terminal Blocks and Barrier Strip
Series	39700
Description	3.50mm Pitch, Eurostyle Fixed-Mount Push-Button Terminal Block, 45° Modular, 5A, 20-16 AWG, Light Gray, 10 Circuits
Application	Wire-to-Board
Component Type	One Piece
Product Name	Eurostyle Fixed Mount
Type	PCB Terminal Blocks and Connectors
UPC	78172542540

Electrical

Current - Maximum per Contact	5.0A
Voltage - Maximum	300V

Physical

Circuits (Loaded)	10
Circuits (maximum)	10
Color - Resin	Gray (Light)
Entry Angle	45° Angle
Lock to Mating Part	None

Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	5.330/g
Number of Rows	1
Orientation	45° Angle
Panel Mount	Yes
Pitch - Mating Interface	3.50mm
Polarized to Mating Part	No
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size (AWG)	16, 18, 20