



Part Number : [397000805](#)


Product Description : 5.00mm Pitch, Eurostyle
Fixed-Mount Push-Button Terminal Block, Horizontal,
10A, 22-14 AWG, Green, 5 Circuits

Series Number : 39700

Status : Active

Product Category : Terminal Blocks and Barrier
Strip

Engineering Part Number : M851-00-1-05-3

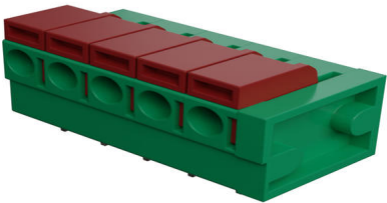

Documents and Resources

Drawings

[397000805_sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

[Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Terminal Blocks and Barrier Strip
Series	39700
Description	5.00mm Pitch, Eurostyle Fixed-Mount Push-Button Terminal Block, Horizontal, 10A, 22-14 AWG, Green, 5 Circuits
Application	Wire-to-Board
Component Type	One Piece
Product Name	Eurostyle Fixed Mount
Type	PCB Terminal Blocks and Connectors
UPC	78172542605

Electrical

Current - Maximum per Contact	10.0A
Voltage - Maximum	300V

Physical

Circuits (Loaded)	5
Circuits (maximum)	5
Color - Resin	Green
Entry Angle	Horizontal
Lock to Mating Part	None

Material - Plating Termination	Tin
Material - Resin	Nylon
Number of Rows	1
Orientation	Horizontal
Panel Mount	Yes
Pitch - Mating Interface	5.00mm
Polarized to Mating Part	No
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size (AWG)	14, 16, 18, 20, 22

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----