


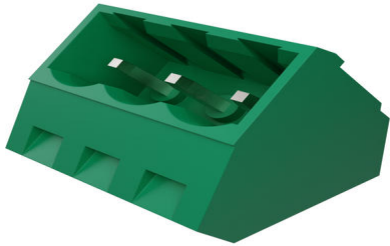

Part Number : [397320003](#)
Product Description : 5.00mm Pitch Eurostyle 45°
Angle PCB Header, Closed Ends, 3 Circuits, Green
Series Number : 39732
Status : Active
Product Category : Terminal Blocks and Barrier
Strip
Engineering Part Number : M750S-08-1-03-3



Documents and Resources

Drawings

[397320003 sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Reviewed per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Not Reviewed per EU 2015/863

[Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Terminal Blocks and Barrier Strip
Series	39732
Description	5.00mm Pitch Eurostyle 45° Angle PCB Header, Closed Ends, 3 Circuits, Green
Application	Wire-to-Board
Component Type	PCB Header
Product Name	Eurostyle Pluggable
Type	PCB Terminal Blocks and Connectors
UPC	78172544095

Electrical

Current - Maximum per Contact	15.0A
Voltage - Maximum	300V

Physical

Circuits (Loaded)	3
Circuits (maximum)	3
Color - Resin	Green
Entry Angle	N/A
Lock to Mating Part	Yes
Material - Metal	Brass

Material - Plating Mating	Tin
Material - Resin	Polyamide
Number of Rows	1
Orientation	45° Angle
Panel Mount	N/A
PC Tail Length	3.50mm
Pitch - Mating Interface	5.00mm
Pitch - Termination Interface	5.00mm
Polarized to Mating Part	Yes
Shrouded	Fully
Stackable	No
Temperature Range - Operating	-40° to +105°C
Termination Interface Style	Through Hole